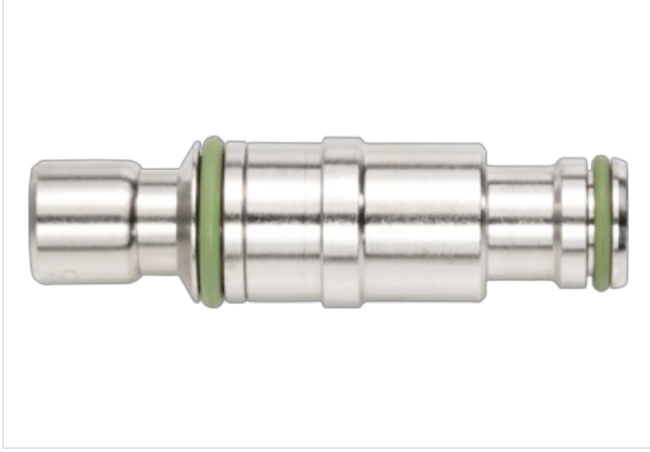


MODL. VARIO insert for coupling housing type B

8/6 shut-off, stainless steel type 1.4404 (V4A)

Modlink Vario
Stainless steel 1.4404 (V4A)
with shut-off
AD8

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27260702
ECLASS-6.1	27260708
ECLASS-7.0	27440312
ECLASS-8.0	27440312
ECLASS-9.0	27440312
ECLASS-10.1	27440312
ECLASS-11.1	27440312
ECLASS-12.0	27440312
ETIM-5.0	EC002641
GTIN	4048879574242
Gümrük tarife no (gtip)	73269098
Paket miktarı	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67, IP68
Degree of protection (ISO 20653:2013)	IP66K, IP69K
Additional condition protection degree	inserted, screwed

Mechanical data

Barrier	with shut-off
Operating pressure min.	0 bar
Operating pressure max.	16 bar

Mechanical data | Material data

Material gasket	FPM
Material housing	Stainless steel 1.4404 (V4A)

Mechanical data | Mounting data

Outer diameter hose 8 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	120 °C