


MODL. VARIO insert for coupling housing type B

8/6 no shut-off, nickel plated brass

Insert - mobile housing
Brass, nickel plated
without shut-off
AD8

Ürün Linki

örnekleme

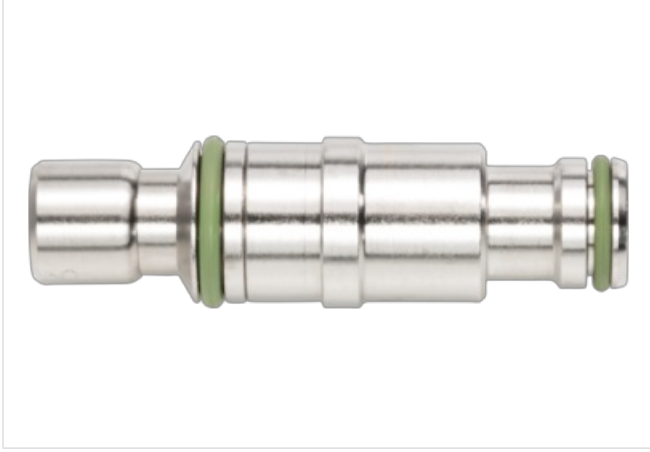

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27260702
ECLASS-6.1	27260708
ECLASS-7.0	27440312
ECLASS-8.0	27440312
ECLASS-9.0	27440312
ECLASS-10.1	27440312
ECLASS-11.1	27440312
ECLASS-12.0	27440312
ETIM-5.0	EC002641
GTIN	4048879572255
Gümrük tarife no (gtip)	74198090
Paket miktarı	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67, IP68
Degree of protection (ISO 20653:2013)	IP66K, IP69K
Additional condition protection degree	inserted, screwed

Mechanical data

Barrier	without shut-off
Operating pressure min.	-0,8 bar
Operating pressure max.	16 bar

Mechanical data | Material data

Coating housing	nickel plated
Material gasket	FPM
Material housing	Brass

Mechanical data | Mounting data

Outer diameter hose 8 mm

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 120 °C