

SIEMENS CONTACTOR SUPPRESSOR

RC, 230VAC/DC



230 V AC/DC

RC

For other configurations and voltages, please inquire.

Ürün Linki

örnekleme

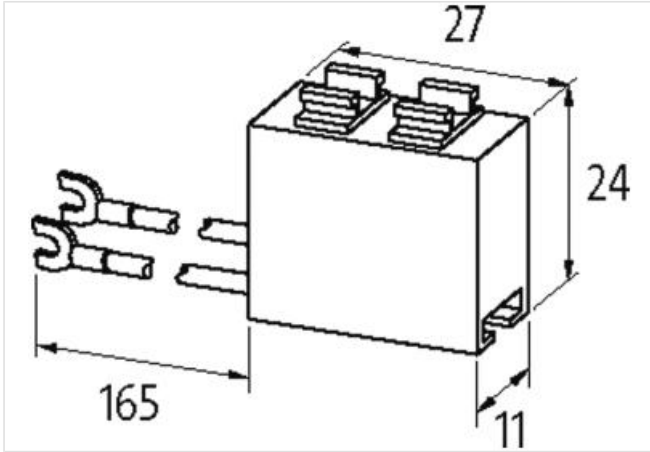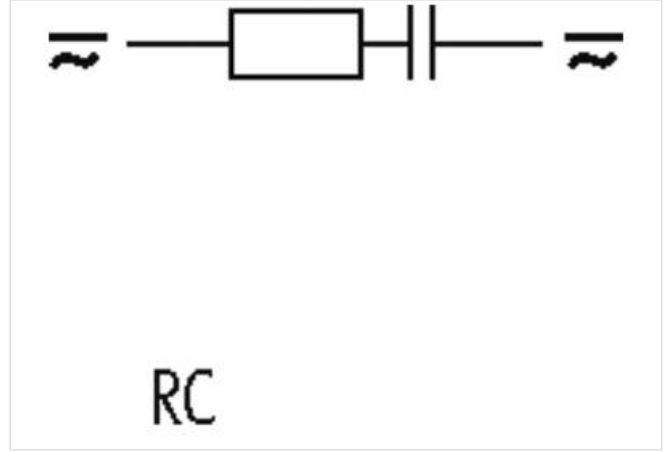

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
GTIN	4048879019781
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Compatibility Compatible with	
Appropriate contactors	3 TH 3/4/8; 3 TF 30...45; 3 TB 40...3 TB 44
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	127 V
Input voltage AC max.	240 V
Input voltage DC min.	127 V
Input voltage DC max.	240 V
Installation Connection	
Connection information	self-securing cable forks
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	11 mm
Width	27 mm
Depth	24 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C