

**MOTOR SUPPRESSOR**

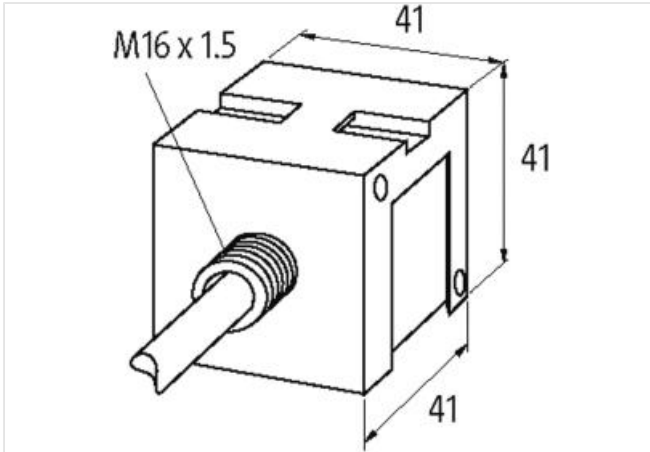
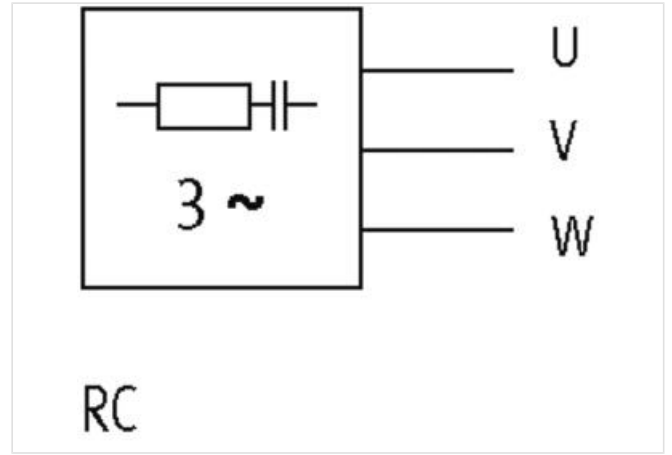
RC, 3x400VAC/10kW

3x 400 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

For DIN-rail mounting use 2xArt.-No. 20900 adapter feet  
approx. 500 mm, PVC cable 3x 0.75 mm<sup>2</sup>

**Ürün Linki****örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

|            |          |
|------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-8.0 | 27371013 |

|                                                 |                                |
|-------------------------------------------------|--------------------------------|
| ECLASS-9.0                                      | 27371013                       |
| ECLASS-10.1                                     | 27371013                       |
| ECLASS-11.1                                     | 27371013                       |
| ECLASS-12.0                                     | 27371013                       |
| ETIM-5.0                                        | EC000197                       |
| GTIN                                            | 4048879019569                  |
| Gümrük tarife no (gtip)                         | 85363010                       |
| Paket miktarı                                   | 1                              |
| <b>Electrical data   Supply</b>                 |                                |
| Power frequency                                 | 50 ... 60 Hz                   |
| <b>Electrical data   Input</b>                  |                                |
| Input voltage AC                                | 400 V                          |
| <b>Installation</b>                             |                                |
| Connection cross section max.                   | 0,75 mm²                       |
| <b>Installation   Connection</b>                |                                |
| Family construction form                        | free cable end                 |
| <b>Installation   Pin assignment</b>            |                                |
| No. of poles                                    | 3                              |
| <b>Device protection   Media</b>                |                                |
| Flame resistance                                | flame retardant                |
| <b>Mechanical data   Material data</b>          |                                |
| Combustibility class housing (UL94)             | V-0                            |
| Material housing                                | Plastic                        |
| Material potting compound                       | 2-component epoxy              |
| <b>Mechanical data   Mounting data</b>          |                                |
| Mounting method                                 | geschnappt                     |
| Suitable for mounting type                      | Mounting rail TH35, (EN 60715) |
| Height                                          | 41 mm                          |
| Width                                           | 41 mm                          |
| Depth                                           | 41 mm                          |
| <b>Environmental characteristics   Climatic</b> |                                |
| Operating temperature min.                      | -20 °C                         |
| Operating temperature max.                      | 60 °C                          |