

ALLEN-BRADLEY CONTACTOR SUPPRESSOR

Varistor, 24VAC/DC



24 V AC/DC

VDR

For other configurations and voltages, please inquire.

Ürün Linki

örnekleme

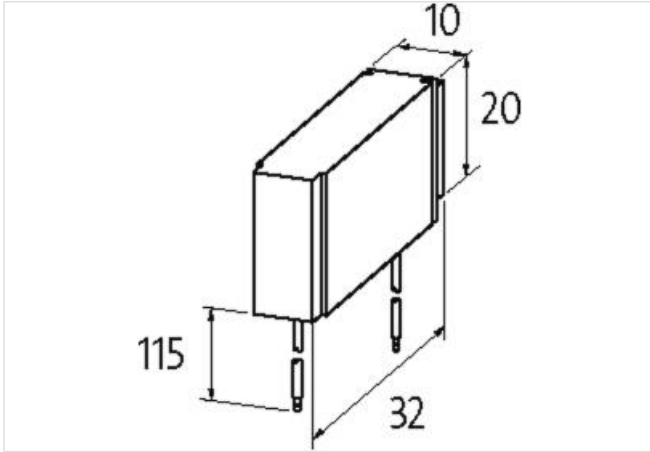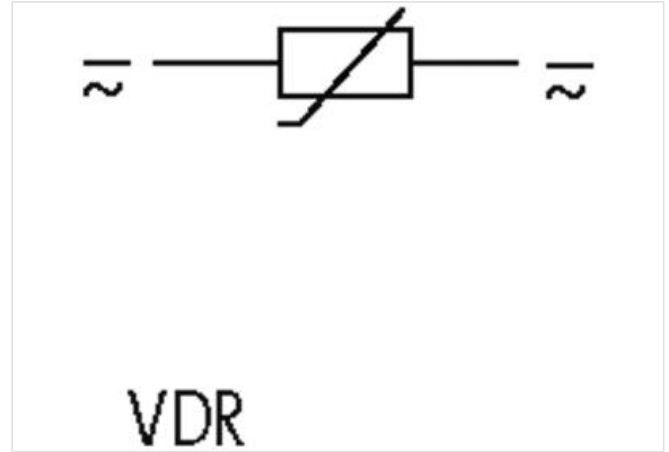

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
GTIN	4048879017848
Gümrük tarife no (gtip)	85363010
Paket miktarı	1

Compatibility | Compatible with

Appropriate contactors	100-M
------------------------	-------

Electrical data

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.
Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalı sınırlıdır. Sürüm: 2024-05-06

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Damping factor	1.5× UN
----------------	---------

Electrical data | Input

Input voltage AC min.	24 V
-----------------------	------

Input voltage AC max.	30 V
-----------------------	------

Input voltage DC min.	24 V
-----------------------	------

Input voltage DC max.	30 V
-----------------------	------

Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
-------------------------------------	-----

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Height	20 mm
--------	-------

Width	10 mm
-------	-------

Depth	32 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	70 °C
----------------------------	-------