



**SV-SUB D 25ST.-KL FOR SIGNAL TRANSFER**

125 VAC/DC / 2 A

Male connector  
25-pole  
Screw terminals

**Ürün Linki**

örnekleme

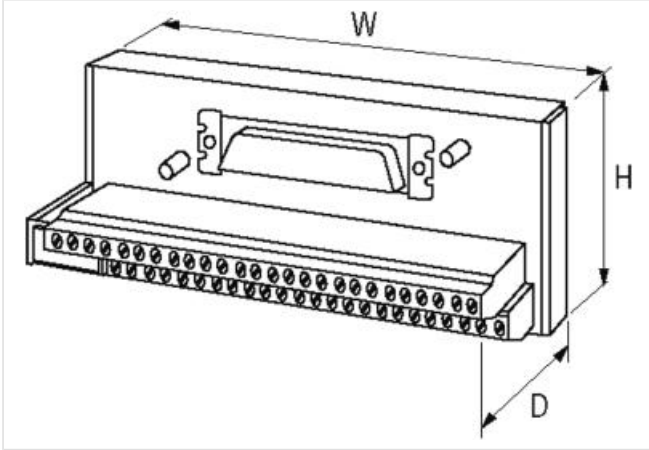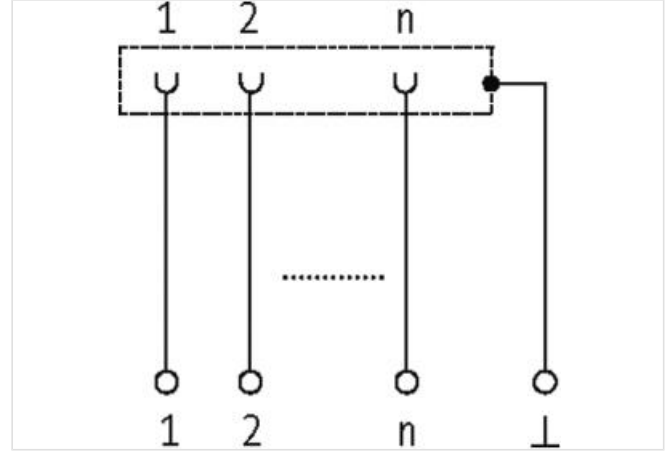

Ürün Image farklı olabilir

**Ticari bilgiler**

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27143424 |
| ECLASS-6.1  | 27260708 |
| ECLASS-7.0  | 27141152 |
| ECLASS-8.0  | 27141152 |
| ECLASS-9.0  | 27141152 |
| ECLASS-10.1 | 27141152 |

|                                                 |                                                |
|-------------------------------------------------|------------------------------------------------|
| ECLASS-11.1                                     | 27141152                                       |
| ECLASS-12.0                                     | 27141152                                       |
| ETIM-5.0                                        | EC001283                                       |
| GTIN                                            | 4048879026529                                  |
| Gümrük tarife no (gtip)                         | 85366990                                       |
| Paket miktarı                                   | 1                                              |
| <b>Electrical data   Supply</b>                 |                                                |
| Operating voltage AC                            | 125 V                                          |
| Operating voltage DC                            | 150 V                                          |
| Operating current max.                          | 2 A                                            |
| <b>Device protection   Electrical</b>           |                                                |
| Overvoltage category (EN 60664-1)               | II                                             |
| <b>Mechanical data   Mounting data</b>          |                                                |
| Mounting method                                 | geschnappt                                     |
| Suitable for mounting type                      | mounting rail, (EN 60715)                      |
| Height                                          | 63 mm                                          |
| Width                                           | 95 mm                                          |
| Depth                                           | 48 mm                                          |
| Looking techniques                              | Standard UNC 4-40 screw thread bolt (EN 60807) |
| <b>Environmental characteristics   Climatic</b> |                                                |
| Operating temperature min.                      | -20 °C                                         |
| Operating temperature max.                      | 70 °C                                          |