



SV-2 X SUB D 15 -KL. FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Female connector
15-pole
Screw terminals

Ürün Linki

örnekleme

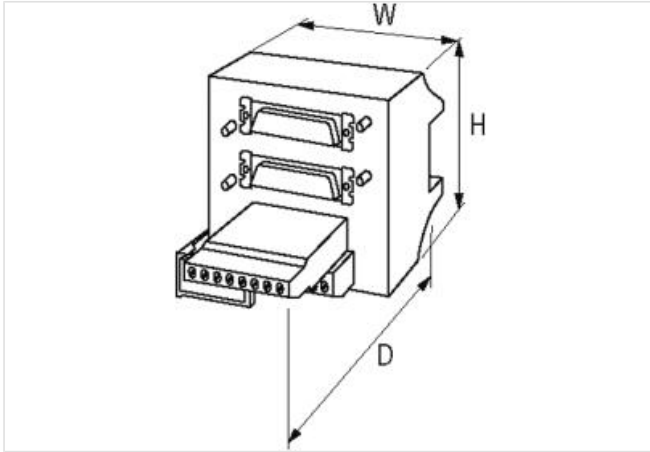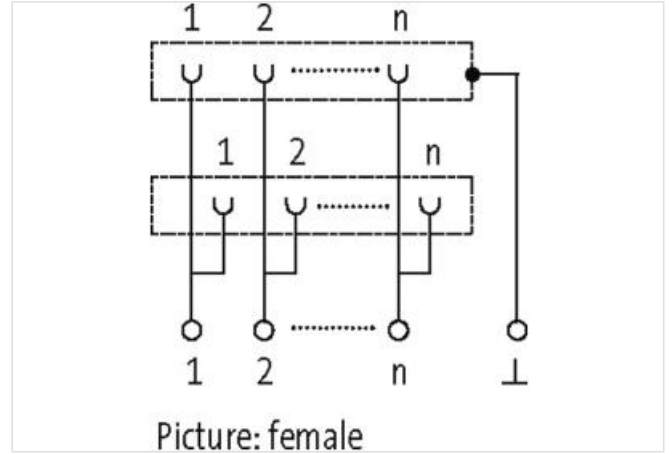

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152

ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
GTIN	4048879026154
Gümrük tarife no (gtip)	85366990
Paket miktarı	1
Electrical data Supply	
Operating voltage AC	125 V
Operating voltage DC	150 V
Operating current max.	2 A
Device protection Electrical	
Overvoltage category (EN 60664-1)	I
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	70 mm
Depth	66 mm
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C