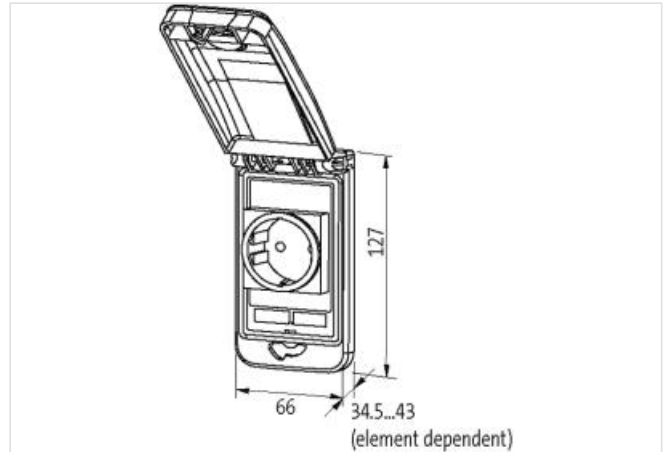
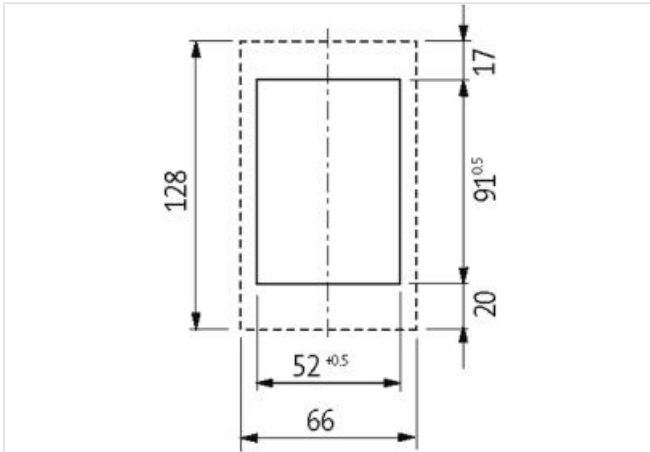
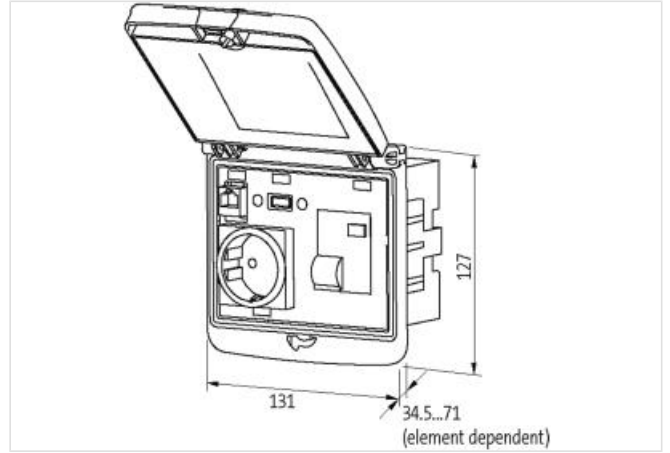


MODLINK MSDD FRAME SINGLE METALIC

Closure 3 mm double bit incl. pluggable knob

Frame: plastic PA black

Lid: plastic, ABS gray

Closure: 3 mm double bit
with attachable rotation knob**Ürün Linki****örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27189217
ECLASS-6.1	27189260
ECLASS-7.0	27189260
ECLASS-8.0	27189260
ECLASS-9.0	27189260
ECLASS-10.1	27182810

ECLASS-11.1	27182810
ECLASS-12.0	27182810
ETIM-5.0	EC002625
GTIN	4048879368834
Gümrük tarife no (gtip)	85389099
Paket miktarı	1

Mechanical data | Mounting data

Height	127 mm
Width	66 mm
Depth	43 mm

Frame

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Color cover	metallic
Color housing	black
Material lid	ABS
Material housing	PA