



 
MEF EMC-FILTER 3-PHASE 2-STAGE

I:50A U:3x500 VAC book-style

50 A
2-

[Link to Product](#)

Illustration

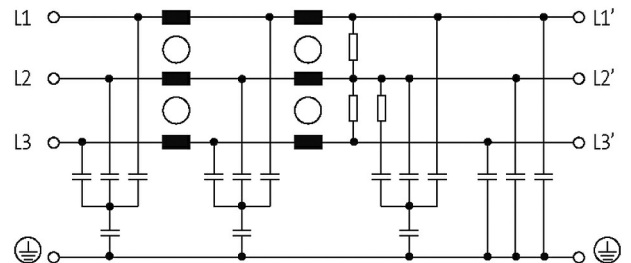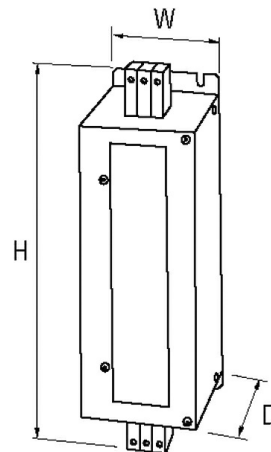

Product may differ from Image



	max. 3 x 500 V AC
	50...60 Hz
	18 x IN t ≤ 0.5 ms; 1.5 x IN t ≤ 1 min. (1 x)
	max. 15 mA (250 V AC)
	0.5 16 mm ² AWG 20 5 ; 0.5 10 mm ² AWG 20 7
	3.3 kV (L-N), 2 s; 3.1 kV (L-L), 2 s
	,
HxWxD	295x70x177 mm
	25/085/21 (EN 60068-1)
	3 1-/2- EMC MEF 3/1-3/2 0.1 30 MHz TN-C IT 10
EAN	4048879029124
eClass	27130806
HS	85363030
Packaging unit	1
	IT