

MOELLER CONTACTOR SUPPRESSOR



RC, 110/230VAC

110 V AC/DC
230 V AC/DC
RC

For other configurations and voltages, please inquire.

Link to Product

Illustration

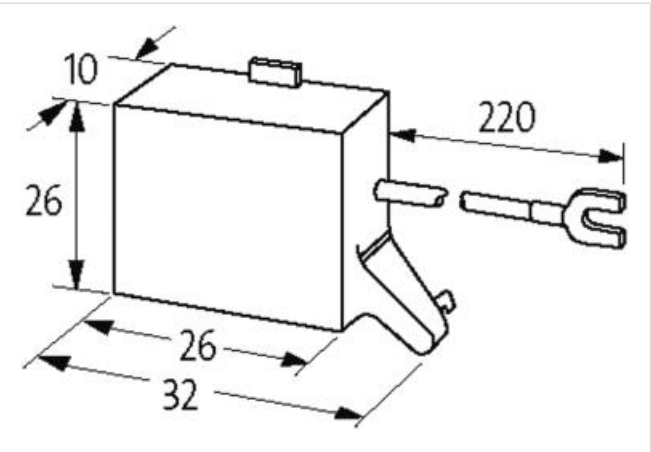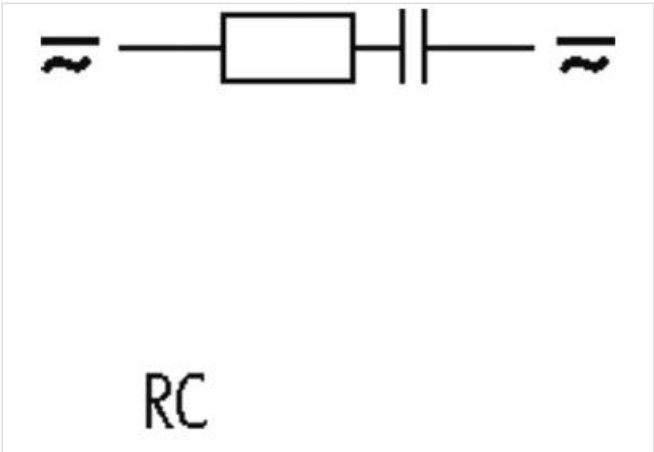

Product may differ from Image



取引条件	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
GTIN	4048879020190
HSコード	85363010
Packaging unit	1
Compatibility Compatible with	
Appropriate contactors	XTMC, DIL E...
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	110 V
Input voltage AC max.	250 V
Input voltage DC min.	110 V
Input voltage DC max.	250 V
Installation Connection	
Connection information	self-securing cable forks
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	27,5 mm
Width	10 mm
Depth	32 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C