

ALLEN-BRADLEY CONTACTOR SUPPRESSOR

RC, 240VAC/DC



230 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

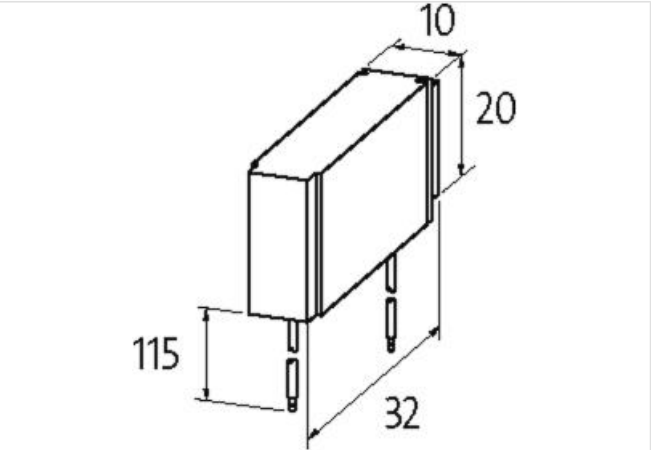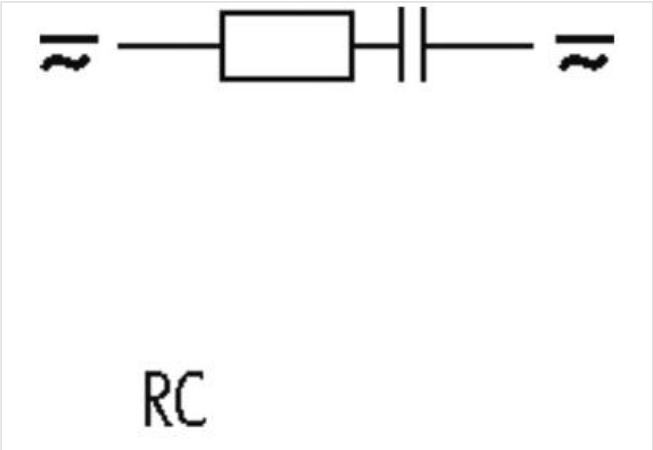

Product may differ from Image



取引条件	
ECLASS-6.0	27371013
GTIN	4048879020060
HSコード	85363010
Packaging unit	1
Compatibility Compatible with	
Appropriate contactors	100-M
Electrical data	

Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	110 V
Input voltage AC max.	250 V
Input voltage DC min.	110 V
Input voltage DC max.	250 V
Installation Connection	
Connection information	flexible connection wires
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	20 mm
Width	10 mm
Depth	32 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C