



MOTOR SUPPRESSOR

RC, 3x575VAC/7,5kW

RC  
PG9  
3× 575 V AC  
Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.  
For DIN-rail mounting use 2×Art.-No. 20900 adapter feet  
approx. 500 mm, PVC cable 3× 0.75 mm²

Link to Product

Illustration

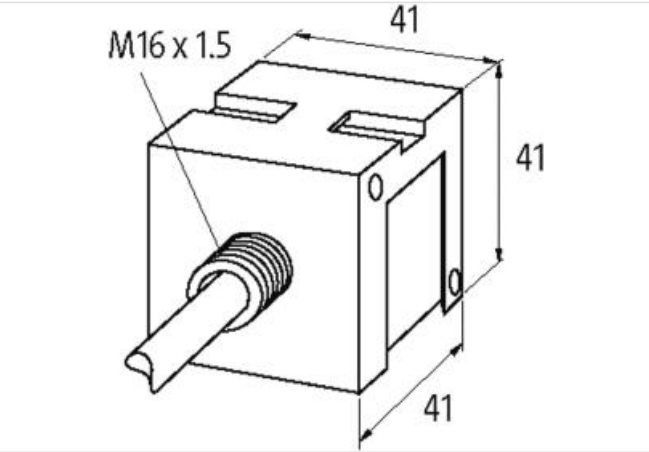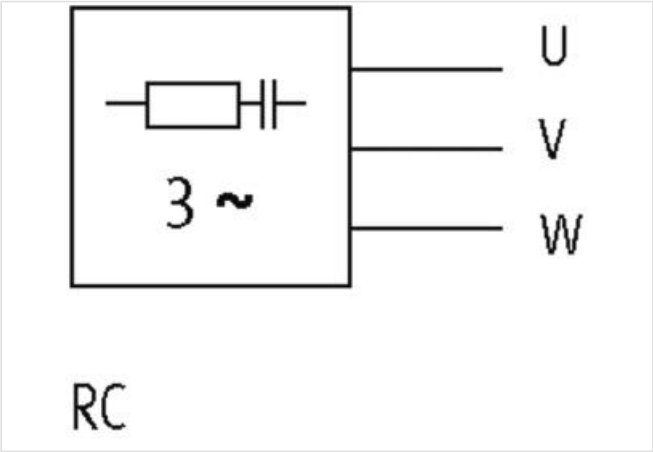

Product may differ from Image



| 取引条件       |          |
|------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |

|                                          |                                |
|------------------------------------------|--------------------------------|
| ECLASS-8.0                               | 27371013                       |
| ECLASS-9.0                               | 27371013                       |
| ECLASS-10.1                              | 27371013                       |
| ECLASS-11.1                              | 27371013                       |
| ECLASS-12.0                              | 27371013                       |
| ETIM-5.0                                 | EC000197                       |
| GTIN                                     | 4048879019491                  |
| HSコード                                    | 85363010                       |
| Packaging unit                           | 1                              |
| Electrical data   Supply                 |                                |
| Power frequency                          | 50 ... 60 Hz                   |
| Electrical data   Input                  |                                |
| Input voltage AC                         | 575 V                          |
| Installation                             |                                |
| Connection cross section max.            | 0,75 mm²                       |
| Installation   Connection                |                                |
| Family construction form                 | free cable end                 |
| Installation   Pin assignment            |                                |
| No. of poles                             | 3                              |
| Device protection   Media                |                                |
| Flame resistance                         | flame retardant                |
| Mechanical data   Material data          |                                |
| Combustibility class housing (UL94)      | V-0                            |
| Material housing                         | Plastic                        |
| Material potting compound                | 2-component epoxy              |
| Mechanical data   Mounting data          |                                |
| Mounting method                          | geschnappt                     |
| Suitable for mounting type               | Mounting rail TH35, (EN 60715) |
| Height                                   | 41 mm                          |
| Width                                    | 41 mm                          |
| Depth                                    | 41 mm                          |
| Environmental characteristics   Climatic |                                |
| Operating temperature min.               | -20 °C                         |
| Operating temperature max.               | 60 °C                          |