



MOTOR SUPPRESSOR

Varistor, 3x575VAC/20kW

3× 575 V AC
VDR-(1) per phase
Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

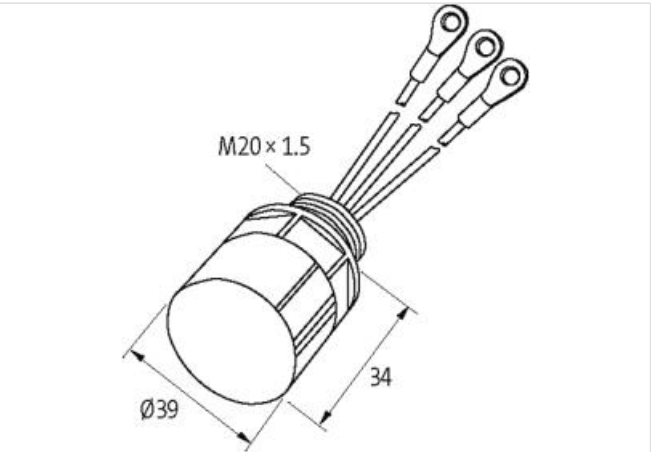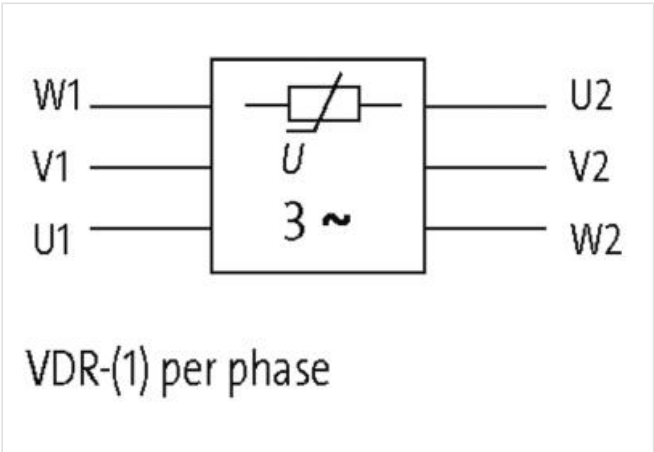

Product may differ from Image



取引条件	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879019088
HSコード	85363010
Packaging unit	1
Electrical data Supply	
Power frequency	10 ... 400 Hz
Electrical data Input	
Input voltage AC	575 V
Installation	
Connection cross section max.	1 mm ²
Installation Connection	
Connection information	Single strands
Length single strands	150 mm
Ring terminals	M6isolated
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	39 mm
Width	39 mm
Depth	44 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C