



SIEMENS CONTACTOR SUPPRESSOR

Diode, 0...240VDC

24 V DC  
Diode/Z-Diode  
Mounts on the underside of the contactor  
For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

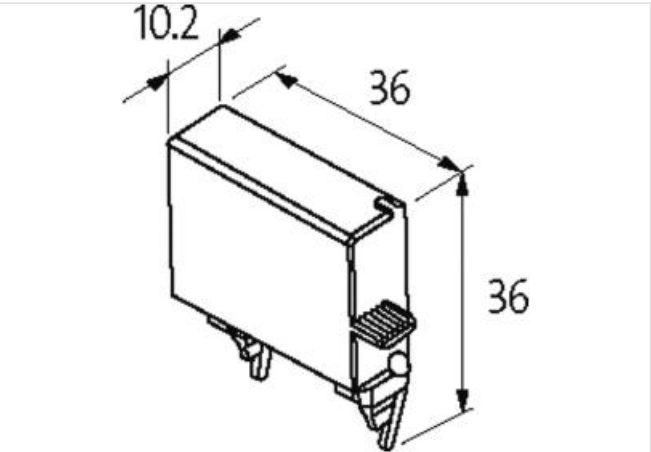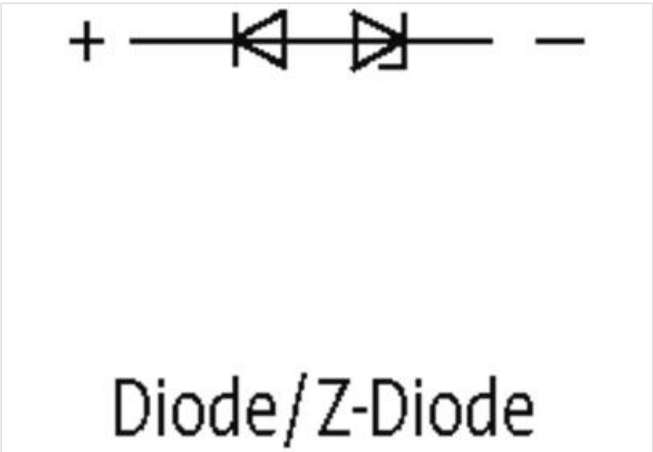

Product may differ from Image



| 取引条件        |          |
|-------------|----------|
| ECLASS-6.0  | 27371013 |
| ECLASS-6.1  | 27371013 |
| ECLASS-7.0  | 27371013 |
| ECLASS-8.0  | 27371013 |
| ECLASS-9.0  | 27371013 |
| ECLASS-10.1 | 27371013 |

|                                          |                  |
|------------------------------------------|------------------|
| ECLASS-11.1                              | 27371013         |
| ECLASS-12.0                              | 27371013         |
| ETIM-5.0                                 | EC002498         |
| GTIN                                     | 4048879017503    |
| HSコード                                    | 85363010         |
| Packaging unit                           | 1                |
| Compatibility   Compatible with          |                  |
| Appropriate contactors                   | 3 RT 10.24/25/26 |
| Electrical data                          |                  |
| Damping factor                           | 1.5× UN          |
| Electrical data   Input                  |                  |
| Input voltage DC min.                    | 0 V              |
| Input voltage DC max.                    | 30 V             |
| Installation   Connection                |                  |
| Connection information                   | Plug contact     |
| Device protection   Media                |                  |
| Flame resistance                         | flame retardant  |
| Mechanical data   Material data          |                  |
| Combustibility class housing (UL94)      | V-0              |
| Material housing                         | Plastic          |
| Mechanical data   Mounting data          |                  |
| Height                                   | 36 mm            |
| Width                                    | 36 mm            |
| Depth                                    | 10,2 mm          |
| Environmental characteristics   Climatic |                  |
| Operating temperature min.               | -20 °C           |
| Operating temperature max.               | 70 °C            |