

MVP12, 6XM12, 5POLE, PLUGGABLE CABLE

3.0m PUR/PVC 12x0,34+3x0,75

ケーブル長はご要望に応じます。

耐油・耐薬品に優れたプラスチックハウジング

強い薬品等に対する耐性は個々のアプリケーションごとに試験すべきです。詳細はお問い合わせください。

6ポート, 5極


PUR/PVC

3.0 m

デジタルPNPシグナル 24 V DC用LED付き

[Link to Product](#)**Illustration**

M12 Females 5-pole

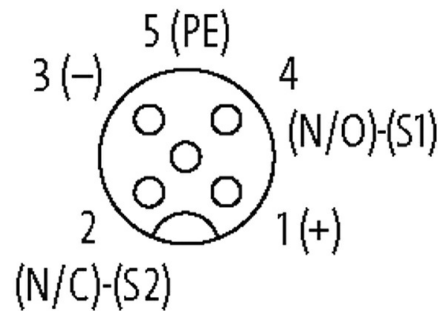

Product may differ from Image

認証**General data**

Temperature range	-20...+80 °C
Dimensions H×W×D	125×50.2×17 mm

Technical Data

Operating voltage	24 V DC ±25%
Housing	プラスチック, 難燃材
Protection	IP65 および IP67 ネジ締込時 (EN 60529)

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 03/21

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Material	PBT
Operating current per contact	max. 4 A
Signal per port	2
Total current	max. 8 A
Locking of ports	ネジ山 (M12×1 mm)

Cables

Cable number	388
No./diameter of wires	12× 0.34 + 3× 0.75 mm ²
Wire isolation	PVC (黄茶, 赤, 灰桃, 白, 赤青, 緑, 白緑, 黄, 茶緑, 灰, 白黄, 桃, 茶, 緑黄, 青)
C-track properties	2 Mio.
Jacket Color	灰色
Material (jacket)	PUR/PVC
Outer Ø	9.8 mm ±5%
Bend radius (fixed)	10× 外径
Bend radius (moving)	12× 外径
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+70 °C
Color (jacket)	灰色

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(アース)
	LED (緑): 電源 / LED (黄色): (S1/S2)

取引条件

EAN	4048879064507
eClass	27279219
HSコード	85369010
Packaging unit	1
生産現国	DE