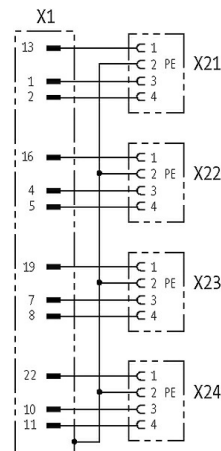
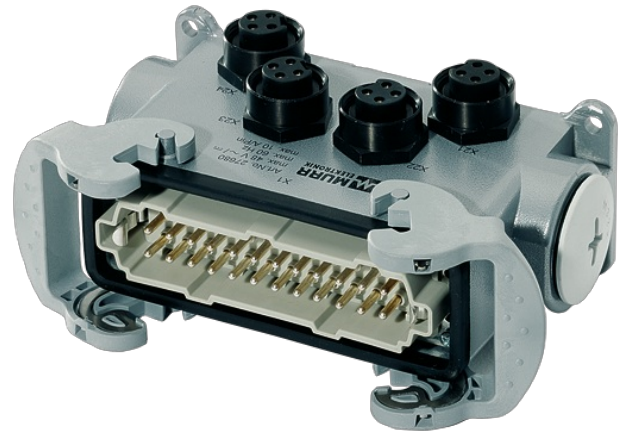


**POWER DISTRIBUTOR PD4 7/8" 4 POLE**

24+E male to 4 x 7/8" 4-pole female

産業用オスプラグ 24+PE  
to 4x 7/8" UNF メス  
4極

[Link to Product](#)**Illustration**

Product may differ from Image

**Technical Data**

Operating voltage	50 V AC/120 V DC (SELV)
Operating current per contact	max. 9 A
Protection	IP67 ネジ締込時 (EN 60529)
Housing	アルミニウムダイキャスト (粉体塗装)
Locking of ports	2-手動固定 (2 クランプ)

**General data**

Temperature range	-30...+85 °C
Dimensions H×W×D	165×70×100 mm

**取引条件**


EAN	4048879063456
-----	---------------

eClass 27279219

HSコード 85369010

Packaging unit 1

生産現国 CZ

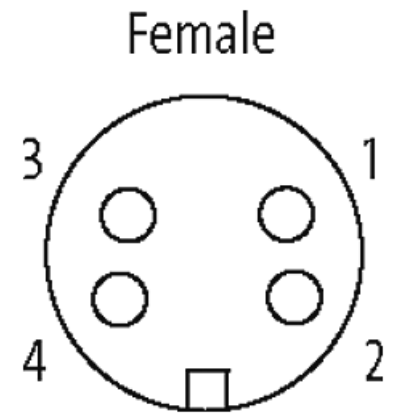**Sketch**

Product may differ from Image