


MUW ANALOG COUPLER COMPONENT

Product discontinued, no alternative

[Link to Product](#)

Illustration

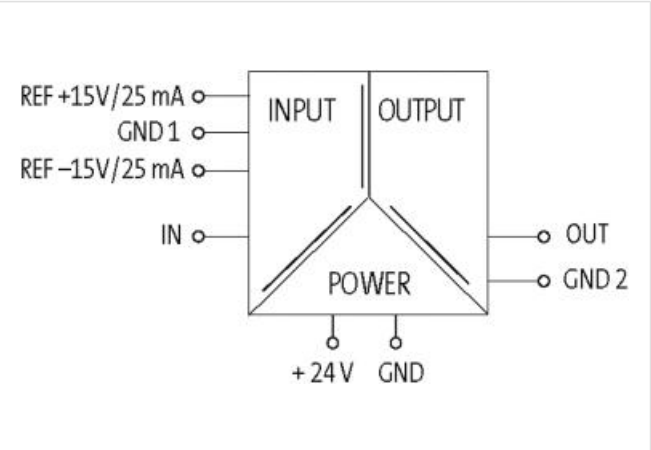

Product may differ from Image

取引条件	
ECLASS-6.0	27210990
ECLASS-7.0	27210990
ECLASS-8.0	27210990
ECLASS-9.0	27210990
ETIM-5.0	EC002477
GTIN	4048879028493
HSコード	85437090
Packaging unit	1

Electrical data	
Accuracy (of full scale)	1 %

Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	27,6 V
Operating current max.	200 mA

Electrical data Output	
Working resistance max.	400 Ω

Industrial communication	
Transmission frequency max.	1000 Hz

Device protection Electrical	
Rated surge voltage	1,5 kV

Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	22,5 mm
Depth	102 mm

Environmental characteristics Climatic	
--	--

Operating temperature min.	0 °C
Operating temperature max.	50 °C