

MUIW ANALOG COUPLER COMPONENT

IN: 0..10 V - OUT: 4..20 mA

INPUT: 0...10 V DC



OUTPUT: 4...20 mA

ネジ端子

入力と出力は電氣的に絶縁

[Link to Product](#)

Illustration

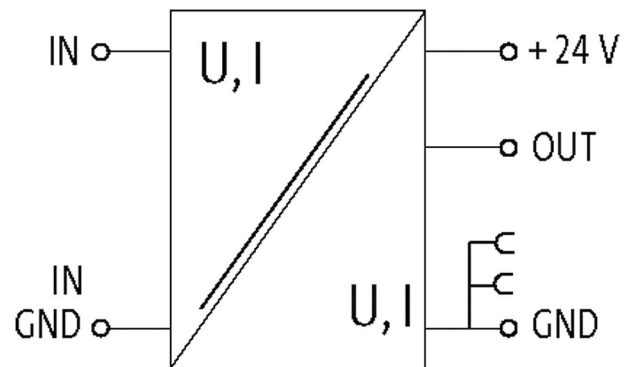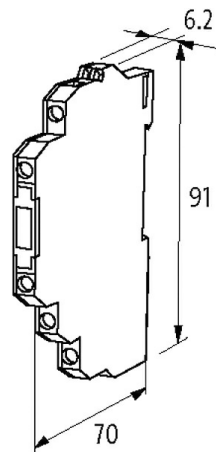

Product may differ from Image

Technical Data

Operating voltage	24 V DC $\pm 20\%$, 平滑
Operating current	50...70 mA
Tolerance	max. 0.5%
Frequency	max. 500 Hz

General data

Test isolation voltage	1.5 kV
Mounting method	DINレール取り付け可能 (EN 60715)
Temperature range	0...+60 °C
Dimensions H×W×D	91×6.2×70 mm

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 03/21

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Description	
Functional description	Murr社のアナログコンバータは標準的な信号 (0 ~ 10 V, 0 ~ 20 mA, 4 ~ 20 mA) を電氣的に絶縁してこれら3つのうちの1種の信号に変換します。内臓の電流制限器により、短絡、過負荷保護されています。モジュール MIIW - 0/4 ~ 20 mA to 0/4 ~ 20 mA - 補助電源無し。
Voltage inputs	
Input resistor	約 200 kΩ
Voltage output signals	
Load	max. 25 mA
Current outputs	
Load	max. 500 Ω
取引条件	
EAN	4048879028394
eClass	27210990
HSコード	85437090
Packaging unit	1
生産現国	CZ