

RMME 11/230 AC INPUT RELAY

IN: 230 VAC/DC - OUT: 125 VAC/DC / 1 A

1リレー; 1 N/Oコンタクト



1 A

230 V AC

ネジ端子

[Link to Product](#)

Illustration

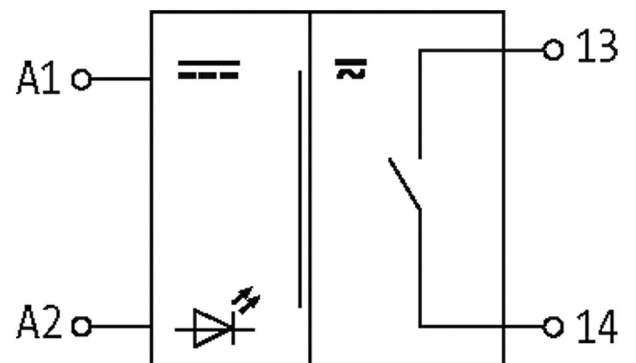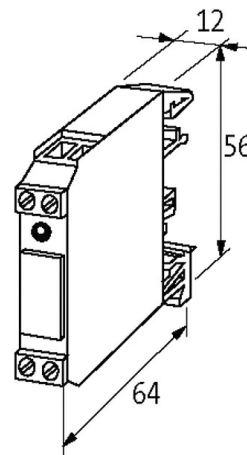

Product may differ from Image

General data

Mech./ elect. life	100 000 000 スイッチングサイクル/負荷
Test isolation voltage	1.5 kV
Mounting method	DINレール取り付け可能 TH35,もしくはG32 (EN 60715)
Temperature range	-20...+60 °C
Dimensions H×W×D	56×12×64 mm

Output

Switching voltage	max. 125 V AC/DC
Switching current per output	max. 1 A
Min. load current	1 mA

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 03/21

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Power rating (voltage dependent)	max. 60 VA/30 W
Switching frequency	max. 15 Hz
Contact material	Pd Ni-Au Rh
Energize/release/contact bounce time	10/10/1 ms

Input

Connection voltage - current	230 V AC (195...253 V AC) - 6 mA
LED display	LED (黄)

Utilization category

AC-12	0.5 A (50 V AC)
AC-15	0.25 A (50 V AC)

取引条件

EAN	4048879027540
eClass	27371001
HSコード	85364900
Packaging unit	1
生産現国	CZ