

MIRO 12.4 24V-2S OUTPUT RELAY



IN: 24 VAC/DC - OUT: 250 VAC/DC / 6 A



2 N/Oコンタクト

6 A

24 V AC/DC

ネジ端子

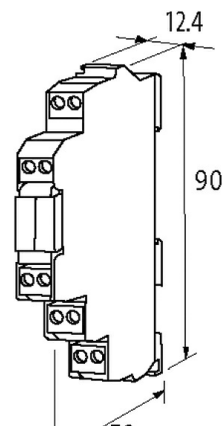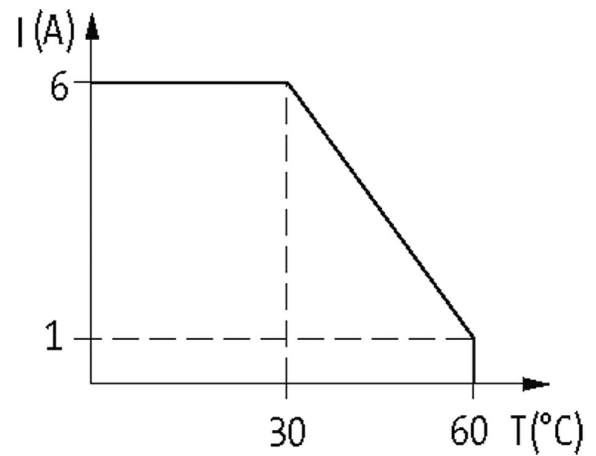[Link to Product](#)**Illustration**

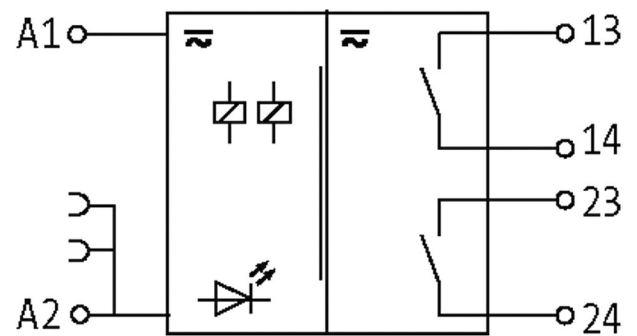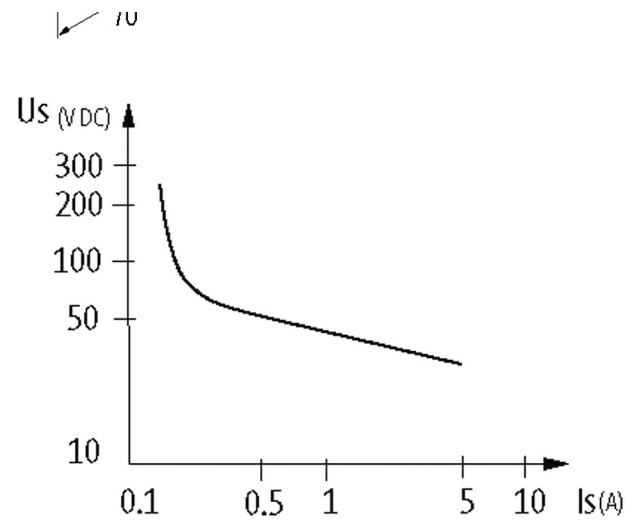

Product may differ from Image

認証



General data

Mech./ elect. life	20 000 000 スイッチングサイクル/負荷
Test isolation voltage	4 kV; 安全分離 (EN 60947-1)
Mounting method	DINレール取り付け可能 (EN 60715)
Temperature range	-20...+55 °C
Dimensions H×W×D	90×12.4×70 mm

Output

Switching voltage	max. 250 V AC/DC
Switching current per output	max. 6 A
Min. load current	100 mA (12 V DC)
Power rating (voltage dependent)	max. 1500 VA/120 W
Switching frequency	max. 10 Hz
Contact material	Ag Sn O ₂
Energize/release/contact bounce time	10/15/1.5 ms

Input

Connection voltage - current	24 V AC/DC (19.2...30 V AC/DC) - 20 mA
LED display	LED (緑)

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 03/21

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Utilization category	
AC-12	6 A (24/110/230 V AC)
AC-15	3 A (24/110/230 V AC)
DC-13	1 A (24 V DC); 0.2 A (110 V DC); 0.1 A (230 V DC)
取引条件	
EAN	4048879027120
eClass	27371001
HSコード	85364900
Packaging unit	1
生産現国	CZ