
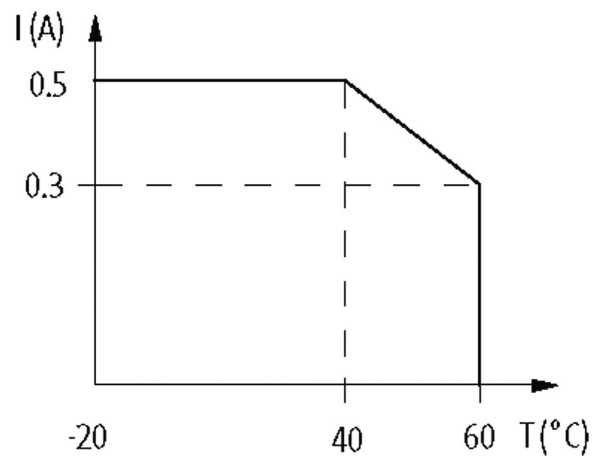
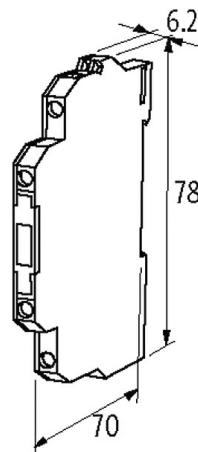


MIRO TH 5VDC SK OPTO-COUPLER MODULE

IN: 5,5 VDC - OUT: 250 VAC / 0,5A

Triac 0.5 A
5 V DC
ネジ端子

[Link to Product](#)**Illustration**

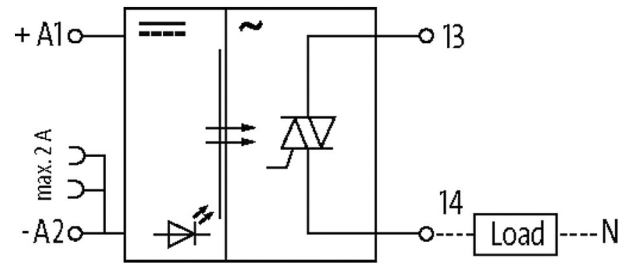

Product may differ from Image

認証



General data

Test isolation voltage	2.5 kV
Mounting method	DINレール取り付け可能 (EN 60715)
Housing	プラスチック 黒, 難燃材
Temperature range	-20...+60 °C
Dimensions H×W×D	78×6.2×70 mm

Output

Switching voltage	24...250 V AC
Switching current per output	2 mA...0.5 A
Saturation voltage (across output)	max. 1.5 V AC
Leakage current (output is open)	max. 0.3 mA
Switching time ON/OFF	10/10 ms
Switching frequency	最大 20 Hz, サプレッションによる

Input

Voltage range ON	4...5.5 V DC
Voltage range OFF	0...2 V DC
Control current	6 mA
LED display	LED (黄)

取引条件

EAN	4048879026772
eClass	27371604
HSコード	85414090
Packaging unit	1
生産現国	CZ