
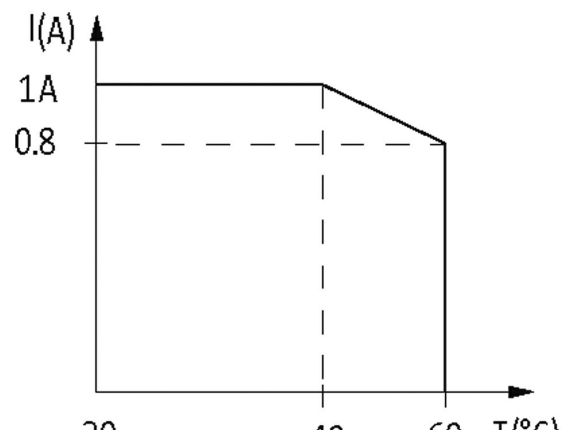
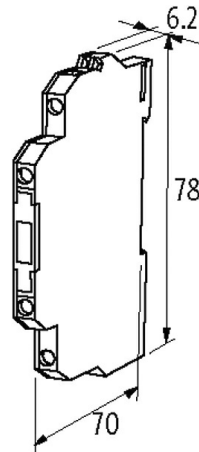


MIRO 6.2 24VDC 250VAC/DC-1A OPTO-COUPLER MODULE

IN: 53 VDC - OUT: 250 VAC / 350 VDC / 1 A

トランジスタ 1 A
24 V DC
ネジ端子
マルチ電圧出力

[Link to Product](#)**Illustration**

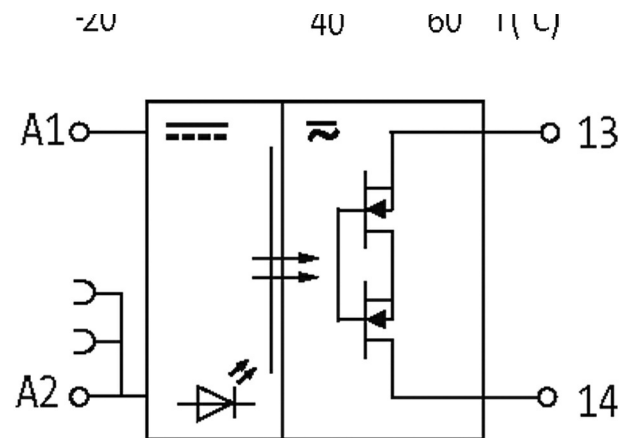

Product may differ from Image

General data

Dimensions H×W×D	78×6.2×70 mm
Test isolation voltage	2.75 kV
Mounting method	DINレール取り付け可能 (EN 60715)
Housing	プラスチック 黒, 難燃材
Temperature range	-20...+60 °C

Output

Switching time ON/OFF	3/6 ms
Switching voltage	5...250 V AC/5...350 V DC
Switching current per output	1 mA...1 A
Saturation voltage (across output)	max. 0.7 V AC/DC
Leakage current (output is open)	max. 25 µA
Switching frequency	max. 10 Hz

Input

Voltage range ON	10...53 V DC
Voltage range OFF	0...5 V DC
Control current	10 mA
LED display	LED (黄)

取引条件

EAN	4048879026727
eClass	27371604
HSコード	85414090
Packaging unit	1
生産現国	CZ