

UFL 20 L PLUG FOR SIGNAL TRANSFER

24 VDC / 1 A - male with LED




リボンケーブルコネクタ LED付き

20極

複合固定機構経由、ストレインリリーフ付/無しコネクタ接続可能

[Link to Product](#)

Illustration

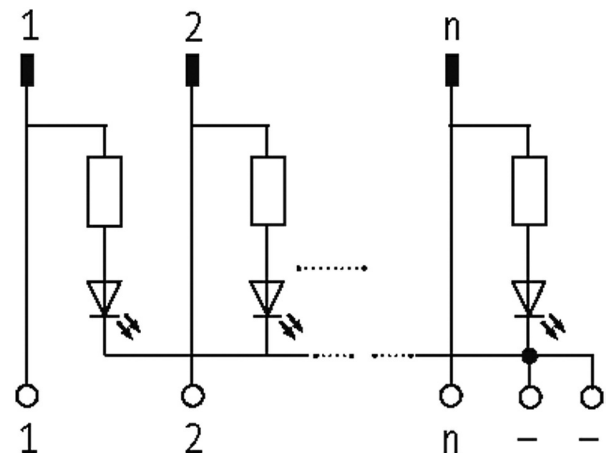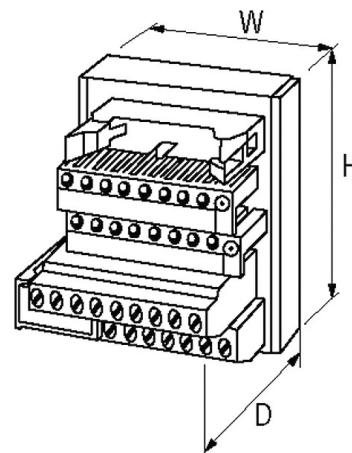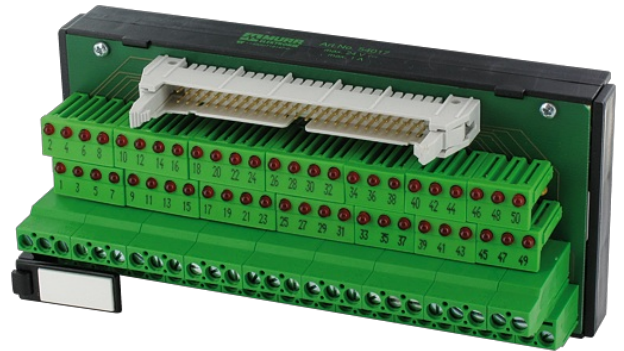

Product may differ from Image

Technical Data

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 02/21

Murrelektronik GmbH | Falkenstr. 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Operating voltage	24 V AC
Operating current per bit	max. 1 A
Material group	EN 60664-1 過電圧, カテゴリII
LED display	LED (赤) Ø 3 mm 各極, acc. to電位 -
Plug connector	ストレインリリーフ付/無しプラグ用 (DIN 41651); ストレインリリーフ付の場合は、ボトムフックの取外しが必要

General data

Dimensions H×W×D	63×75×48 mm
Mounting method	DINレール取り付け可能 (EN 60715)
Temperature range	-20...+70 °C

取引条件

EAN	4048879026604
eClass	27141120
HSコード	85366990
Packaging unit	1
生産現国	CZ