

MA5I67 INSTALLATION TECHNOLOGY


Distribution 1x profile- to 3x profile cable

MA5I67 distribution boxes


1 × on 3 × profile cable

Link to Product

Illustration

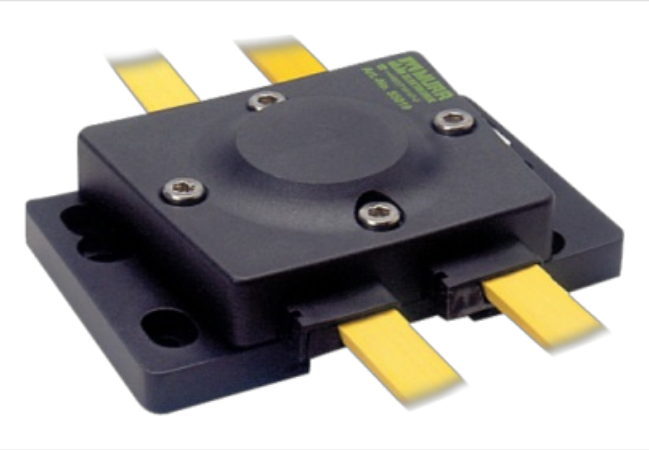

Product may differ from Image

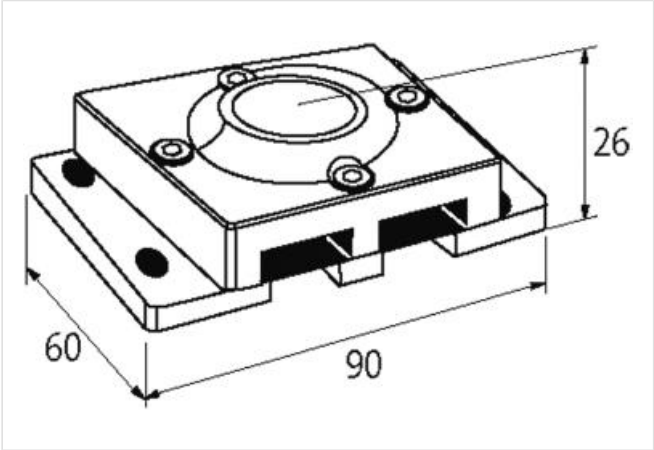

取引条件	
ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
GTIN	4048879052177
HSコード	85369010
Packaging unit	1
Electrical data Supply	
Operating voltage DC max.	36 V
Total current max.	8 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V
Mechanical data Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm

Width	74 mm
Depth	26 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 60664-1