

Xenterra 16TX unmanaged Switch wallmounted 16 Port 100Mbit


16 port unmanaged switch  
Key-hole mounting/screwable  
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

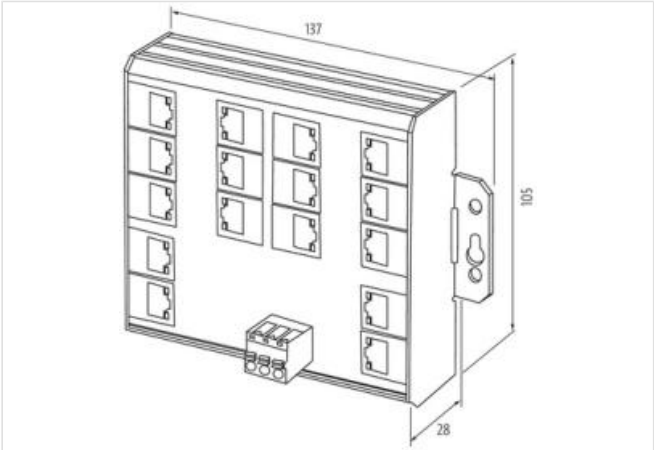

| 取引条件                                              |               |
|---------------------------------------------------|---------------|
| ECLASS-6.1                                        | 19170106      |
| ECLASS-7.0                                        | 19170106      |
| ECLASS-8.0                                        | 19170106      |
| ECLASS-9.0                                        | 19170402      |
| ECLASS-10.1                                       | 19170402      |
| ECLASS-11.1                                       | 19170402      |
| ECLASS-12.0                                       | 19170402      |
| GTIN                                              | 4048879830430 |
| HSコード                                             | 85176200      |
| Packaging unit                                    | 1             |
| Electrical data   Supply                          |               |
| Operating voltage AC min.                         | 8 V           |
| Operating voltage AC max.                         | 28 V          |
| Operating voltage DC min.                         | 9 V           |
| Operating voltage DC max.                         | 36 V          |
| Industrial communication                          |               |
| Data transmission rate max.                       | 100 MBit/s    |
| Industrial communication   Ethernet functionality |               |
| Auto-crossover                                    | yes           |
| Auto-negotiation                                  | yes           |
| duplex                                            | Full duplex   |
| Switch type                                       | unmanaged     |

VLAN unmanaged (IEEE 802.1Q) yes

#### Diagnostics

Alarm contact no

Diagnostic No voltage

LED display Ethernet connection/data traffic

#### Device protection | Electrical

Degree of protection (EN IEC 60529) IP20

#### Mechanical data | Material data

Color housing black

Material housing Metal

#### Mechanical data | Mounting data

Mounting method screwed

Suitable for mounting type Schlüssellochaufhängung

Height 105 mm

Width 137 mm

Depth 28 mm

#### Environmental characteristics | Climatic

Operating temperature min. -40 °C

Operating temperature max. 70 °C

Storage temperature min. -40 °C

Storage temperature max. 85 °C

#### Connection type 1

Connection type 1 16

Family construction form RJ45

Gender female

Color contact carrier black

No. of poles 8

PIN 1 TD +

PIN 2 TD -

PIN 3 RD +

PIN 4 n.c.

PIN 5 n.c.

PIN 6 RD -

PIN 7 n.c.

PIN 8 n.c.