

Memory Card 16GB


UHS class 1, speed class 10
µSD card
16 GB, EXFAT formatted
Industrial standard

Link to Product

Illustration



Product may differ from Image

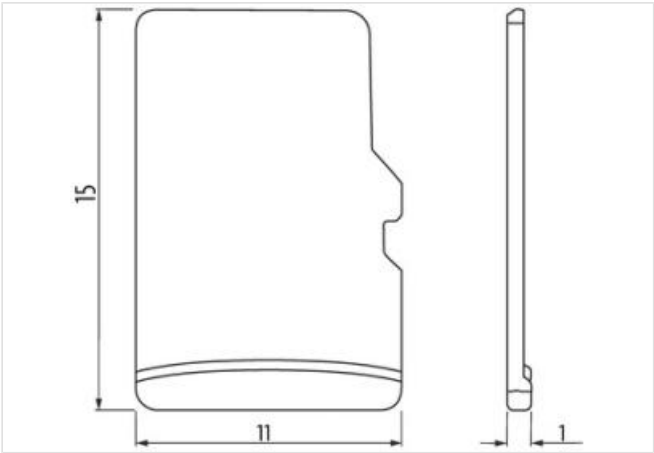

Electrical data | Supply

Power consumption max. 0,66 W

Electrical data | Input

Input voltage DC min. 2,7 V

Input voltage DC max. 3,6 V

Industrial communication | Memory interface

Formatting	EXFAT
Speed class	10
Reading speed max. (data)	90 MBit/s
Writing speed max. (data)	80 MBit/s
Memory card (type)	Micro SD
Memory card max. (capacity)	16 GB
UHS class	I
Transmission mode	SD 1.1, SD 2.0, SD 3.0, SPI

Mechanical data | Mounting data

Height	15 mm
Width	11 mm
Depth	1 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	85 °C
Storage temperature min.	-25 °C
Storage temperature max.	85 °C

取引条件

HSコード	85235110
Packaging unit	1