



IR RELAY SOCKET MODULES

Product discontinued, no alternative

for industrial relays
4 NO/NC contacts
0...230 V AC/DC
without components

[Link to Product](#)

Illustration

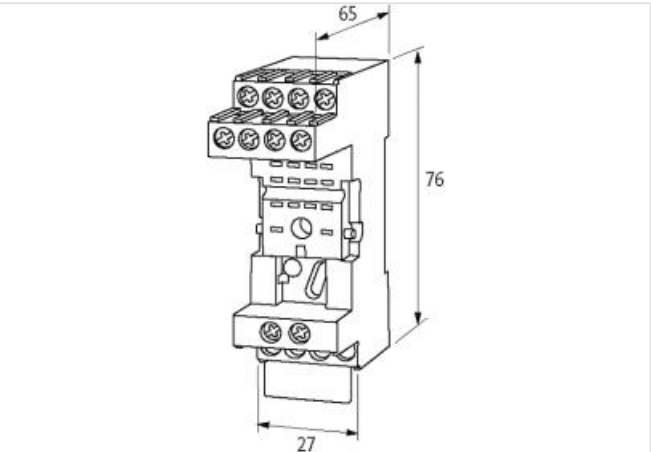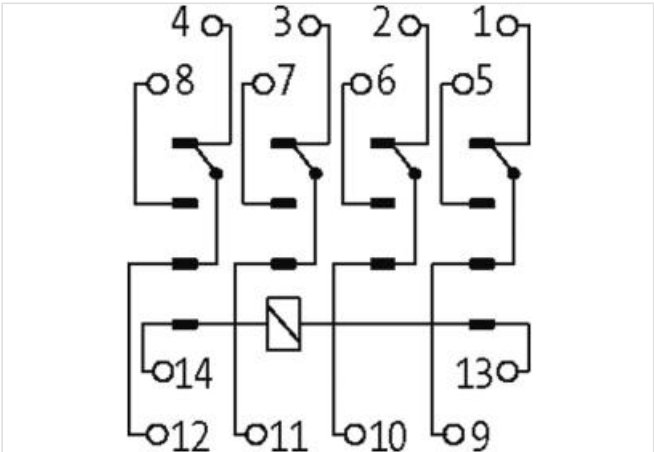

Product may differ from Image



取引条件	
ECLASS-6.0	27371603
ECLASS-7.0	27371603
ECLASS-8.0	27371603
ECLASS-9.0	27371603
ETIM-5.0	EC001437
GTIN	4048879025935

HSコード	85366990
Packaging unit	1
Electrical data Output	
Switching voltage AC max.	250 V
Switching voltage DC max.	110 V
Switching current max.	5 A
Installation Connection	
Connection	Spring clamp terminals FK
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP40
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	76,5 mm
Width	27 mm
Depth	65 mm