

MSVD POWER SOCKET NEMA (GFCI)

Mounting rail

USA (2× NEMA-GFCI 5-20)
(Ground Fault Circuit Interrupter)
Screw terminals


Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

Link to Product

Illustration



Product may differ from Image

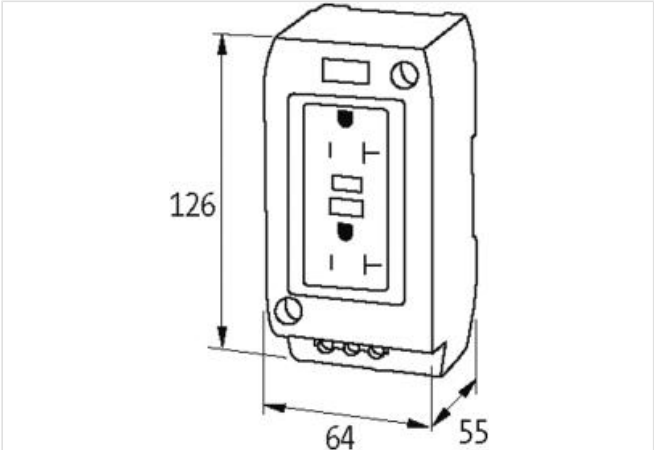

取引条件	
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
GTIN	4048879041386
HSコード	85366990
Packaging unit	1
Electrical data	
Fault current min.	4 mA
Fault current max.	6 mA
Electrical data Supply	
Operating voltage AC	125 V
Operating current max.	20 A
Installation	
Connection cross section max.	6 mm²

Connection Screw terminals SK

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	126 mm
Width	64 mm
Depth	55 mm