

LED-INDICATOR OPAC / YELLOW

LED-110V IP65


(yellow)
110 V AC/DC
The modules are suitable for wall thickness of 1.5...5.0 mm.

Link to Product

Illustration



Product may differ from Image

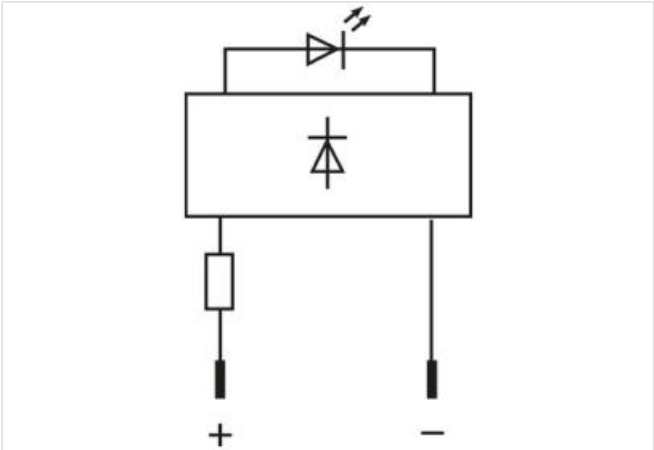

取引条件

ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879041294
HSコード	85318070
Packaging unit	10

Electrical data | Supply

Operating voltage AC	110 V
Operating voltage AC min.	95 V
Operating voltage AC max.	121 V
Operating voltage DC	110 V
Operating voltage DC min.	95 V
Operating voltage DC max.	121 V
Current consumption min.	8 mA
Current consumption max.	12 mA

Installation | Connection

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Device protection Media	
Flame resistance	flame retardant
Mechanical data	
Diameter LED	5 mm
Mechanical data Material data	
Material housing	Plastic
Mechanical data Mounting data	
Diameter front panel drilling	9 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	50 °C