



LED-INDICATOR YELLOW/GREEN

LED 5mm - 24V DC - 15mA - IP40

(yellow/green)
24 V DC
Protection IP40

[Link to Product](#)

Illustration

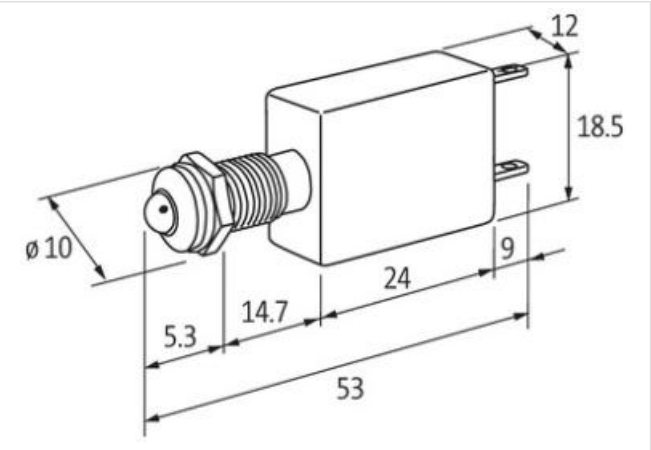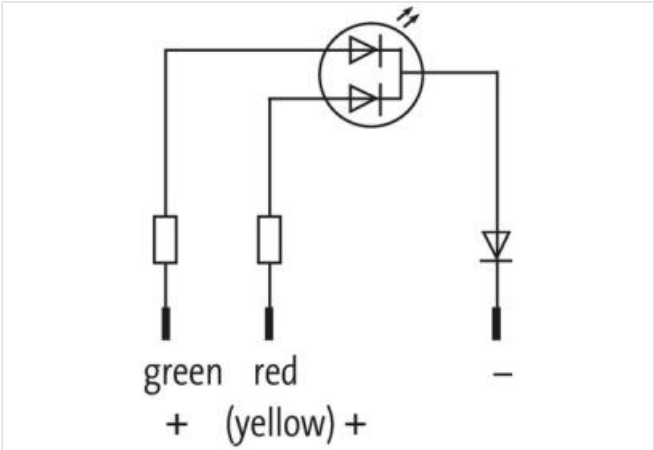

Product may differ from Image

取引条件	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879040846
HSコード	85318070

Packaging unit	10
----------------	----

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption min.	13 mA
Current consumption max.	17 mA

Installation | Connection

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP40
-------------------------------------	------

Mechanical data

Diameter LED	5 mm
--------------	------

Mechanical data | Material data

Color housing	gray
Material housing	PVC

Mechanical data | Mounting data

Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	53 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	70 °C