



LED-DISPLAY YELLOW 110V AC/DC IP67

Product discontinued, no alternative

(yellow)  
110 V AC/DC  
Protection IP67  
with touch protection

Link to Product

Illustration

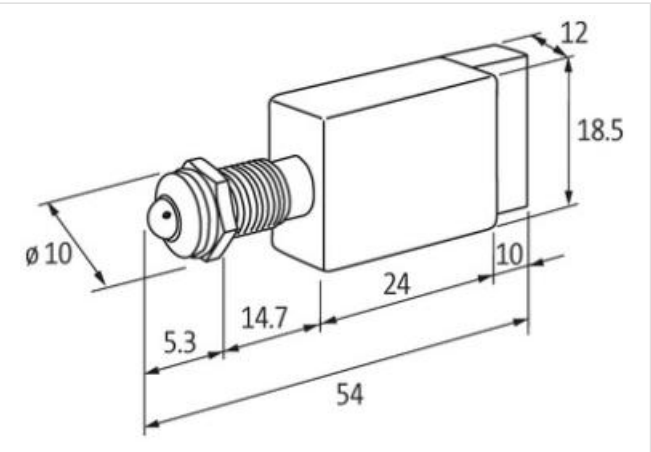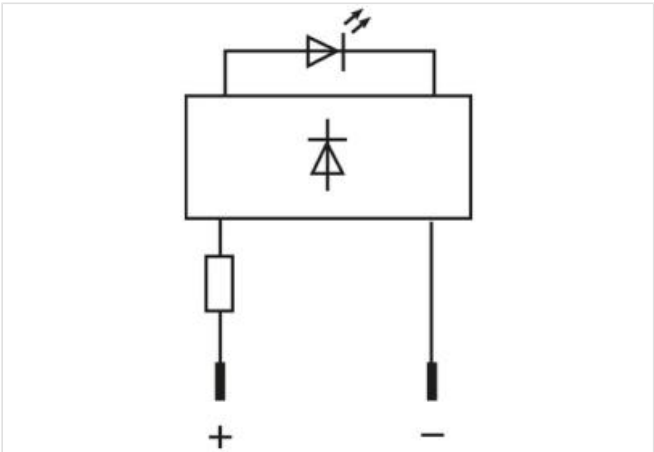

Product may differ from Image

| 取引条件                     |               |
|--------------------------|---------------|
| ECLASS-6.0               | 27261590      |
| ECLASS-7.0               | 27261590      |
| ECLASS-8.0               | 27261590      |
| ECLASS-9.0               | 27261590      |
| ETIM-5.0                 | EC000272      |
| GTIN                     | 4048879040730 |
| HSコード                    | 85318070      |
| Packaging unit           | 10            |
| Electrical data   Supply |               |
| Operating voltage AC     | 110 V         |

|                           |        |
|---------------------------|--------|
| Operating voltage AC min. | 95 V   |
| Operating voltage AC max. | 121 V  |
| Operating voltage DC      | 110 V  |
| Operating voltage DC min. | 95 V   |
| Operating voltage DC max. | 121 V  |
| Current consumption min.  | 4,5 mA |
| Current consumption max.  | 5,5 mA |

**Installation | Connection**

|                        |                   |
|------------------------|-------------------|
| Connection information | Faston 2.8×0.8 mm |
|------------------------|-------------------|

**Device protection | Electrical**

|                                     |      |
|-------------------------------------|------|
| Degree of protection (EN IEC 60529) | IP67 |
|-------------------------------------|------|

**Mechanical data**

|              |      |
|--------------|------|
| Diameter LED | 5 mm |
|--------------|------|

**Mechanical data | Material data**

|                  |      |
|------------------|------|
| Color housing    | gray |
| Material housing | PVC  |

**Mechanical data | Mounting data**

|                               |         |
|-------------------------------|---------|
| Diameter front panel drilling | 8 mm    |
| Height                        | 18,5 mm |
| Width                         | 12 mm   |
| Depth                         | 54 mm   |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -40 °C |
| Operating temperature max. | 70 °C  |