



LED-INDICATOR RED/GREEN

LED 5mm - 24V DC - 15mA - IP67

(red/green)
24 V DC
Protection IP67

[Link to Product](#)

Illustration

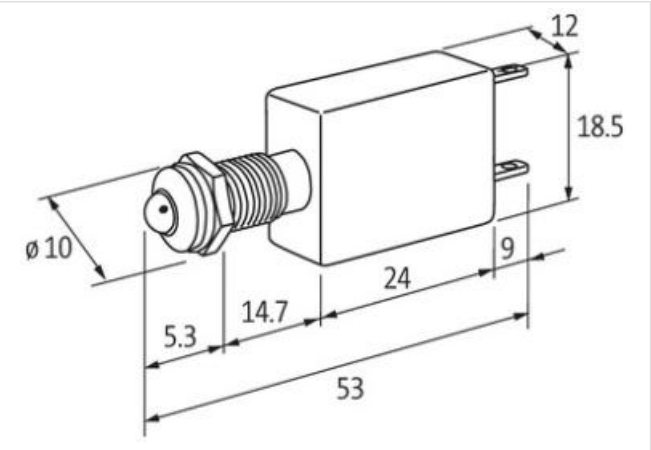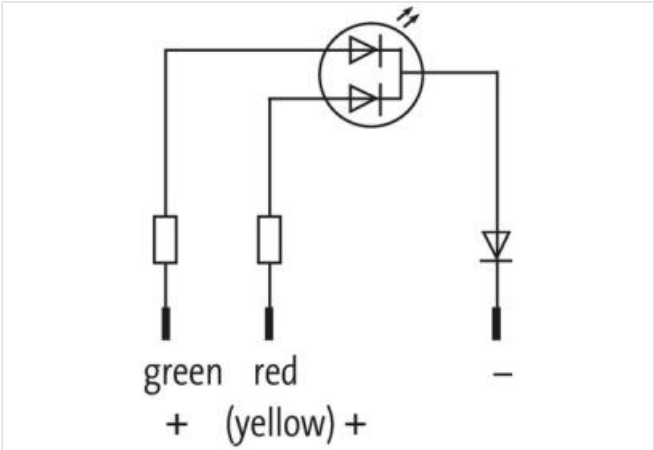

Product may differ from Image

取引条件	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879040563
HSコード	85318070

Packaging unit	10
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption min.	13 mA
Current consumption max.	17 mA
Installation Connection	
Connection information	Faston 2.8×0.8 mm
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Mechanical data	
Diameter LED	5 mm
Mechanical data Material data	
Color housing	gray
Material housing	PVC
Mechanical data Mounting data	
Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	53 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	70 °C