



MIRO 6,2 Valvecontrol 24VDC/1ms

In:24VDC OUT:24VDC/1,5A

Switching accelerator: 1 ms/24 V DC  
Screw terminals

Link to Product

Illustration

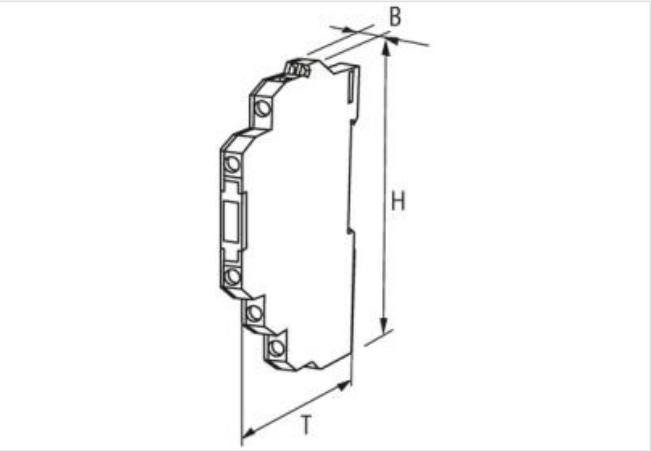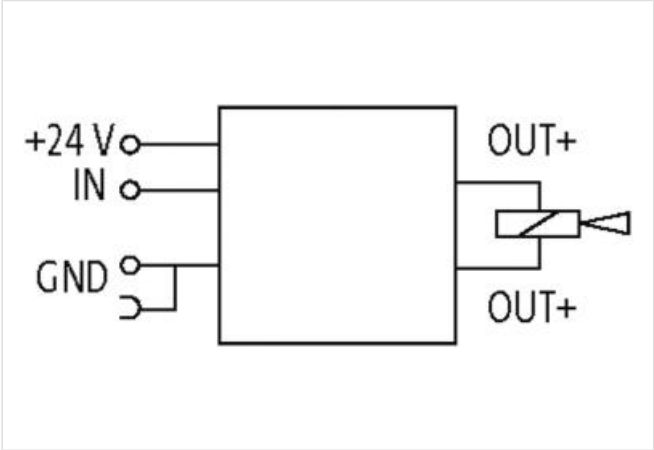

Product may differ from Image



| Electrical data   Input  |        |
|--------------------------|--------|
| Input voltage DC         | 24 V   |
| Input voltage DC min.    | 18 V   |
| Input voltage DC max.    | 30 V   |
| Input current            | 13 mA  |
| Electrical data   Output |        |
| Output current           | 1,5 A  |
| Output current max.      | 0,38 A |

|                             |       |
|-----------------------------|-------|
| Duration surge current max. | 1 ms  |
| Switching frequency max.    | 20 Hz |
| Surge current max.          | 1,5 A |

Mechanical data | Mounting data

|                            |                           |
|----------------------------|---------------------------|
| Mounting method            | geschnappt                |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height                     | 91 mm                     |
| Width                      | 6,2 mm                    |
| Depth                      | 71 mm                     |

Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | 0 °C   |
| Operating temperature max. | 55 °C  |
| Storage temperature min.   | -25 °C |
| Storage temperature max.   | 50 °C  |

Connection type 4

|                          |                    |
|--------------------------|--------------------|
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | black              |
| No. of poles             | 1                  |
| PIN 1                    | GD                 |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | black              |
| No. of poles             | 1                  |
| PIN 1                    | In                 |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | black              |
| No. of poles             | 1                  |
| PIN 1                    | O 1                |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | black              |
| No. of poles             | 1                  |
| PIN 1                    | O 2                |

取引条件

|                |               |
|----------------|---------------|
| GTIN           | 4048879571876 |
| HSコード          | 85437090      |
| Packaging unit | 10            |