



MST SINGLE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:415VA IN:230/400/460VAC±10VAC±20VAC OUT:24/230VAC

Single-phase - Control and Isolation Transformers
415 VA
Isolation class T 40/B
Other voltages on request.

[Link to Product](#)

Illustration

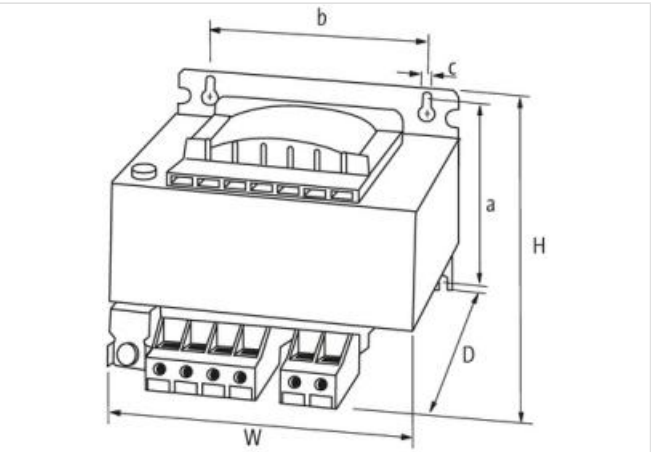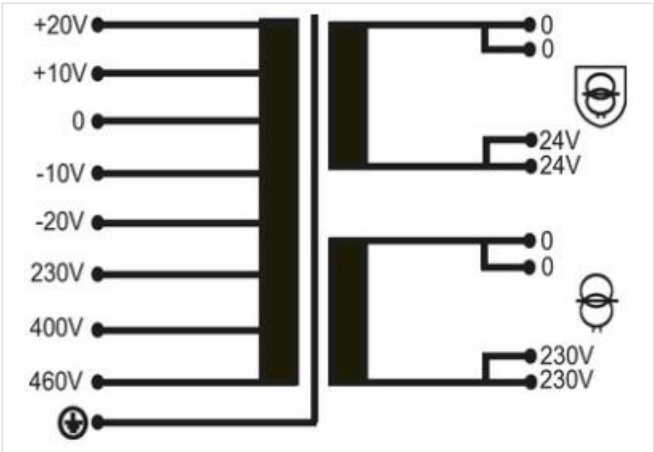

Product may differ from Image



取引条件	
ECLASS-6.0	27031202
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
GTIN	4048879340748
HSコード	85043180
Packaging unit	1
Electrical data	
Security level	SELV
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage 1 AC	230 V
Input voltage 2 AC	400 V
Input voltage 3 AC	460 V
Input current at input voltage 1 AC	2,1 A
Input current at input voltage 3 AC	1 A
Inrush current at input voltage 1	10 A
Inrush current at input voltage 3	5 A
Short-circuit current at input voltage 1	29 A
Short-circuit current at input voltage 3	15 A
Electrical data Output	
Output voltage AC 1	24 V
Output voltage AC 2	230 V
Output voltage adjustable	no
Power rating AC max.	415 VA
Device protection Electrical	
Insulation test voltage input - output	4 kV
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochaufhängung
Mounting dimension a	105,6 mm
Mounting dimension b	122 mm
Mounting dimension c	7 mm
Height	112,5 mm
Width	150 mm
Depth	150 mm
Diameter bore	7 mm
Length bore	11 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-2-4, EN 61558-2-6, EN 62041 category 0
Connection type 4	
Connection type 1	Input
Connection type 2	Output
Connection type 3	Output
Connection	Screw terminals SK
Family construction form	terminal

Gender	female
No. of poles	8
PIN 1	+ 20 V
PIN 2	+ 10 V
PIN 4	- 10 V
PIN 5	- 20 V
PIN 6	230 V
PIN 7	400 V
PIN 8	460 V
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 3	230 V
PIN 4	230 V
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 3	24 V DC
PIN 4	24 V DC
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	metallic
No. of poles	1
PIN 1	PE