



VALVE PLUG SUPPRESSOR FORM BI - 11MM 90°

Diode and LED, 24VDC/50VA/W

24 V DC  
Diode + LED  
Remove plug gasket when fitting adapter. Other LED colors on request.  
Polarity dependent  
Note PIN arrangement (PE at cable outlet of connector). 180° turned version on request.

Link to Product

Illustration

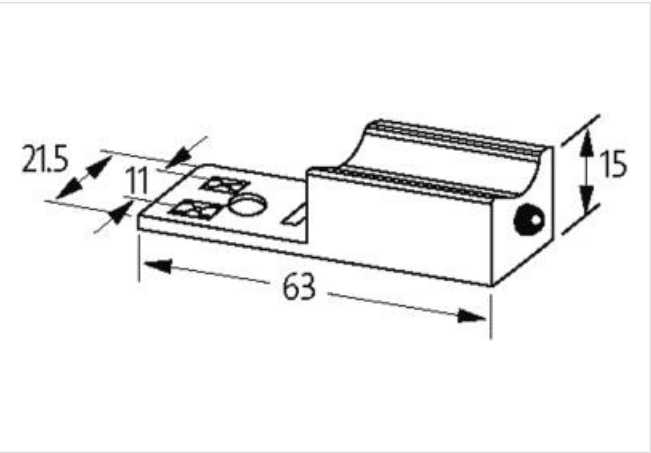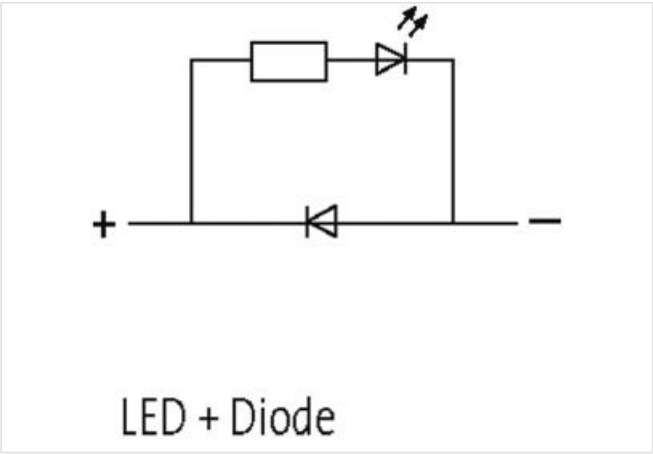

Product may differ from Image



| 取引条件       |          |
|------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-9.0 | 27371013 |

|                                          |                 |
|------------------------------------------|-----------------|
| ECLASS-10.1                              | 27371013        |
| ECLASS-11.1                              | 27371013        |
| ECLASS-12.0                              | 27371013        |
| ETIM-5.0                                 | EC000197        |
| GTIN                                     | 4048879012072   |
| HSコード                                    | 85363010        |
| Packaging unit                           | 1               |
| Electrical data                          |                 |
| Drop-out delay time max.                 | 200 ms          |
| Holding power max.                       | 50 W            |
| Electrical data   Supply                 |                 |
| Cut-off peak voltage max.                | 1 V             |
| Electrical data   Input                  |                 |
| Input voltage DC min.                    | 12 V            |
| Input voltage DC max.                    | 32 V            |
| Diagnostics                              |                 |
| Status indication LED                    | yellow          |
| Device protection   Media                |                 |
| Flame resistance                         | flame retardant |
| Mechanical data   Material data          |                 |
| Coating contact                          | silver-plated   |
| Color housing                            | black           |
| Material housing                         | PA              |
| Material contact                         | Bronze          |
| Mechanical data   Mounting data          |                 |
| Height                                   | 15 mm           |
| Width                                    | 63 mm           |
| Depth                                    | 21,5 mm         |
| Environmental characteristics   Climatic |                 |
| Operating temperature min.               | -20 °C          |
| Operating temperature max.               | 60 °C           |
| Housing temperature max. (EN 61347-2-13) | 130 °C          |