



CAP BIG WITH PLUG. SCREW-TERM. 21-POLE

For use with 4-,6-,8-way d-box M12 5-pole

Cap for 4-, 6-, and 8-way distribution box, 5-pole
Screw plug-in terminals
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

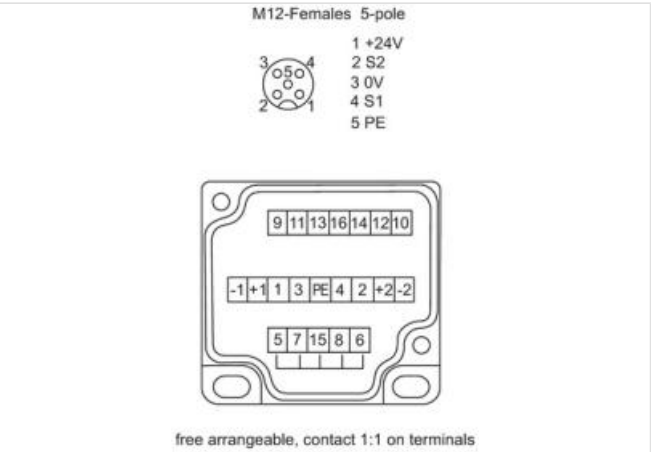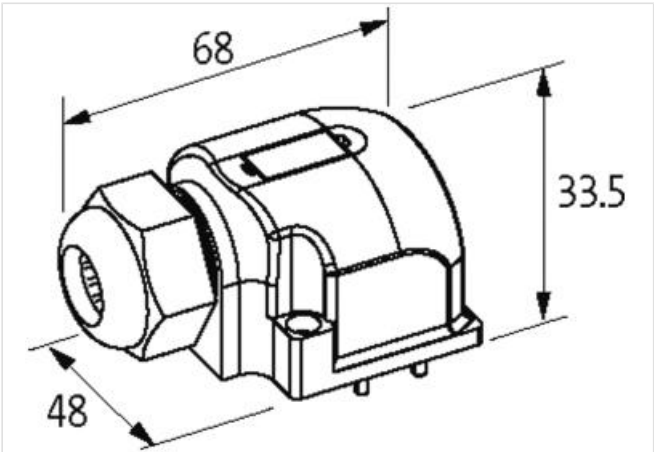

Product may differ from Image

取引条件	
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
GTIN	4048879058025
HSコード	85369010

Packaging unit	1
Electrical data Supply	
Total current max.	8 A
Installation	
Connection cross section max.	1,5 mm²
AWG number max.	16
Installation Connection	
Connection	Screw plug-in terminals
Mechanical data Mounting data	
Height	33,5 mm
Width	48 mm
Depth	68 mm
Connection type 2	
Family construction form	Cap
No. of poles	21
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	24 V DC
PIN 2	S 2
PIN 3	0 V
PIN 4	S 1
PIN 5	PE