
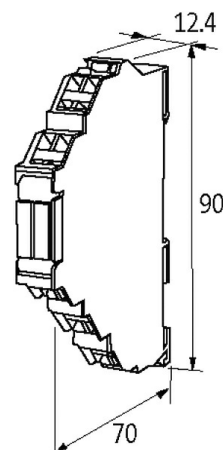
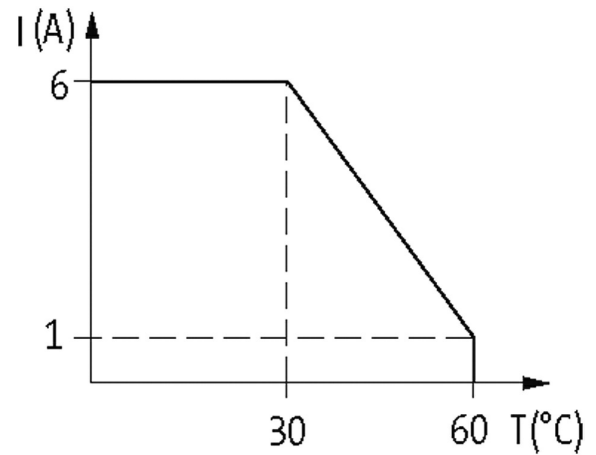
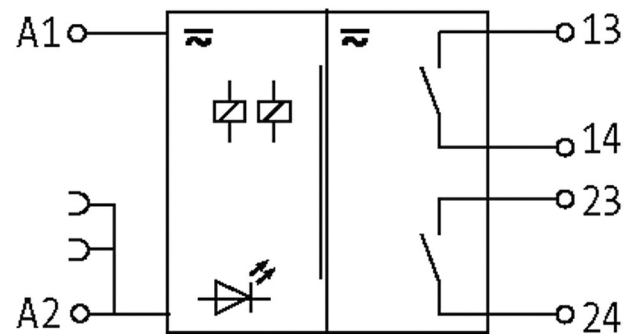


MIRO12.4-1OUTPUT.REL.24V-2S-FK

MIRO 12.4 24V-2S OUTPUT RELAY

2 N/Oコンタクト
6 A
24 V AC/DC
ばね式端子台

[Link to Product](#)**Illustration**

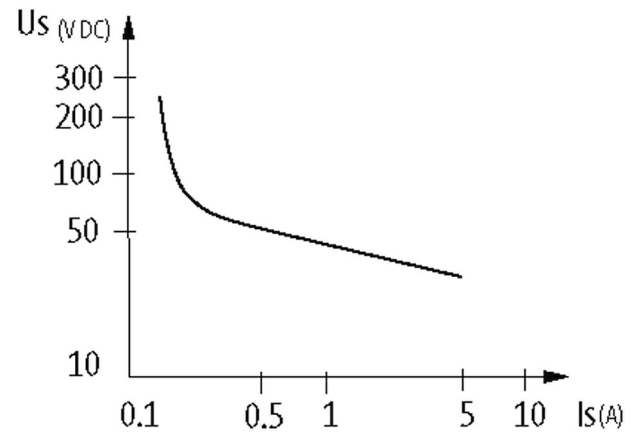

Product may differ from Image

認証



General data

Mech./ elect. life	20 000 000 スイッチングサイクル/負荷
Test isolation voltage	4 kV; 安全分離 (EN 60947-1)
Mounting method	DINレール取り付け可能 (EN 60715)
Temperature range	-25...+60 °C
Dimensions HxWxD	90x12.4x65 mm

Output

Switching voltage	max. 250 V AC/DC
Switching current per output	max. 6 A
Min. load current	100 mA (12 V DC)
Power rating (voltage dependent)	max. 1500 VA/120 W
Switching frequency	max. 10 Hz
Contact material	Ag Sn O2
Energize/release/contact bounce time	10/15/1.5 ms

Input

Connection voltage - current	24 V AC/DC (19.2...30 V AC/DC) - 20 mA
LED display	LED (緑)

Utilization category

AC-12	6 A (24/110/230 V AC)
AC-15	3 A (24/110/230 V AC)
DC-13	1 A (24 V DC); 0.2 A (110 V DC); 0.1 A (230 V DC)
取引条件	
EAN	4048879022064
eClass	27371601
HSコード	85364900
Packaging unit	1
生産現国	CZ