



MIRO TRIAC 1X400VAC-10A

IN: 53 VDC - OUT: 400 VAC / 10 A

Triac 10 A  
24 V DC  
Screw plug-in terminals

[Link to Product](#)

Illustration

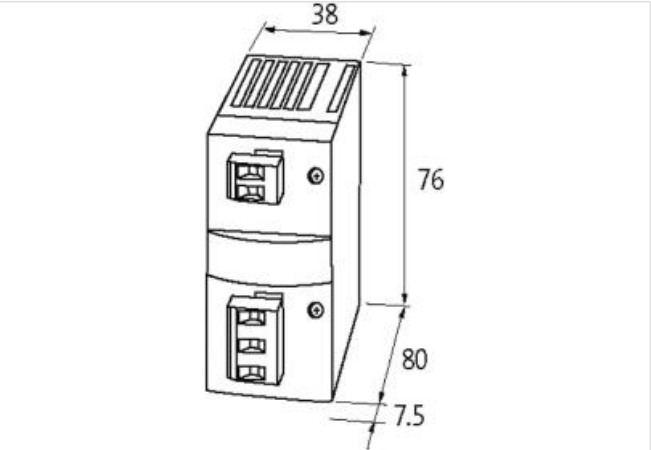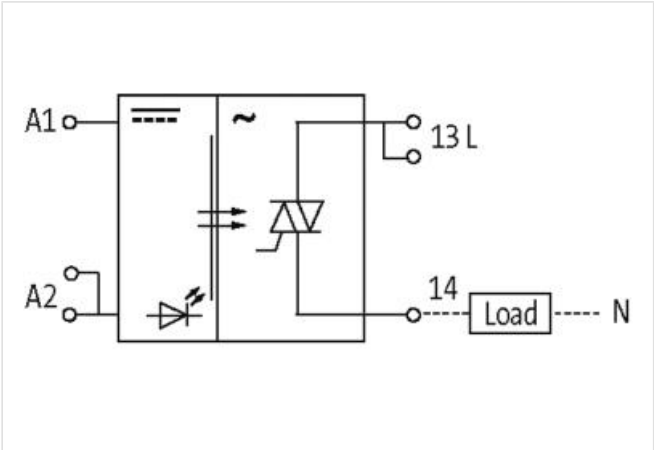

Product may differ from Image



| 取引条件        |          |
|-------------|----------|
| ECLASS-6.0  | 27371604 |
| ECLASS-6.1  | 27371604 |
| ECLASS-7.0  | 27371604 |
| ECLASS-8.0  | 27371604 |
| ECLASS-9.0  | 27371604 |
| ECLASS-10.1 | 27371604 |

|                                          |                           |
|------------------------------------------|---------------------------|
| ECLASS-11.1                              | 27371604                  |
| ECLASS-12.0                              | 27371604                  |
| ETIM-5.0                                 | EC001504                  |
| GTIN                                     | 4048879020985             |
| HSコード                                    | 85414900                  |
| Packaging unit                           | 1                         |
| Electrical data   Input                  |                           |
| Input voltage OFF DC min.                | 0 V                       |
| Input voltage OFF DC max.                | 3 V                       |
| Input voltage DC min.                    | 10 V                      |
| Input voltage DC max.                    | 53 V                      |
| Current input DC                         | 7,8 mA                    |
| Control voltage DC                       | 24 V                      |
| Electrical data   Output                 |                           |
| Switch off delay max.                    | 10 ms                     |
| Duration surge current max.              | 16,6 ms                   |
| Switch on delay max.                     | 10 ms                     |
| Quiescent current OFF max.               | 1 mA                      |
| Switching frequency inductive max.       | 1 Hz                      |
| Switching frequency ohmic max.           | 20 Hz                     |
| Voltage switching AC min.                | 12 V                      |
| Switching voltage AC max.                | 400 V                     |
| Switching current min.                   | 100 mA                    |
| Switching current max.                   | 10 A                      |
| Voltage drop AC max.                     | 0,15 V                    |
| Surge current max.                       | 70 A                      |
| Diagnostics                              |                           |
| Status indication LED                    | green                     |
| Device protection   Media                |                           |
| Flame resistance                         | flame retardant           |
| Mechanical data   Material data          |                           |
| Color housing                            | black                     |
| Material housing                         | Plastic                   |
| Mechanical data   Mounting data          |                           |
| Mounting method                          | geschnappt                |
| Suitable for mounting type               | mounting rail, (EN 60715) |
| Height                                   | 76 mm                     |
| Width                                    | 38 mm                     |
| Depth                                    | 80 mm                     |
| Environmental characteristics   Climatic |                           |
| Operating temperature min.               | -20 °C                    |
| Operating temperature max.               | 60 °C                     |
| Connection type 2                        |                           |
| Connection                               | Spring clamp terminals FK |
| Family construction form                 | terminal                  |
| Gender                                   | female                    |
| Color contact carrier                    | black                     |
| No. of poles                             | 2                         |
| PIN 1                                    | A 2                       |
| PIN 2                                    | A 1                       |
| Connection                               | Spring clamp terminals FK |

|                          |          |
|--------------------------|----------|
| Family construction form | terminal |
| Gender                   | female   |
| Color contact carrier    | black    |
| No. of poles             | 3        |
| PIN 1                    | 14       |
| PIN 2                    | 13       |
| PIN 3                    | 13       |