



EUROCARD HOLDER

SKP 24/7-M-FK

Spring clamp terminals  
24-, 7-pole M (EN 60603)  
Row z, b, d  
With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.  
The D2 size is for a card without a front plate.  
To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

Link to Product

Illustration

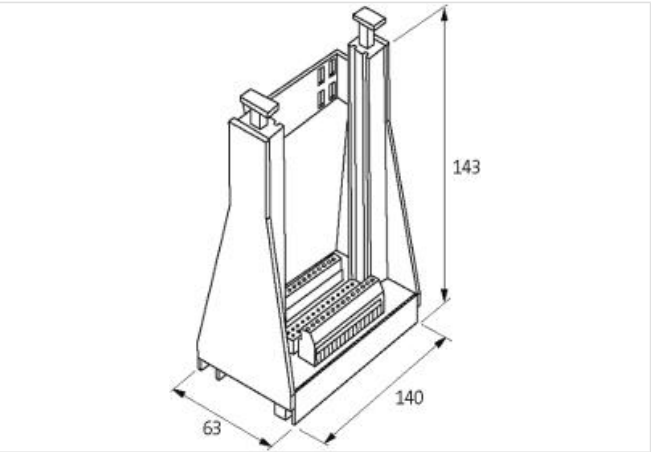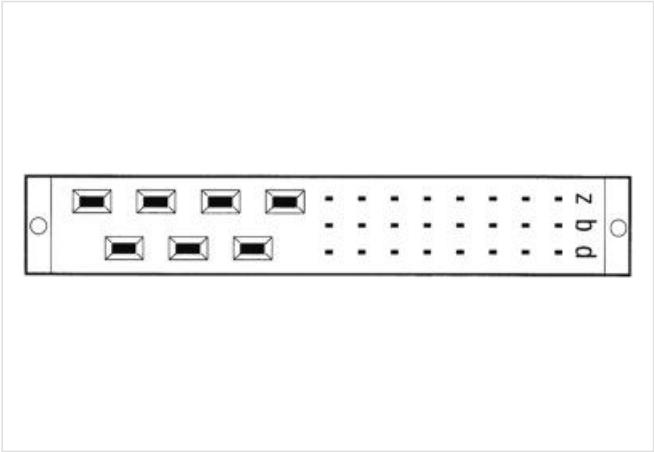

Product may differ from Image



| Side 1                 |       |
|------------------------|-------|
| Operating voltage AC   | 500 V |
| Operating current max. | 4 A   |
| No. of poles           | 7     |

| Side 2                 |       |
|------------------------|-------|
| Operating voltage AC   | 250 V |
| Operating current max. | 15 A  |
| No. of poles           | 24    |

| 取引条件           |               |
|----------------|---------------|
| ECLASS-6.0     | 27260710      |
| ECLASS-6.1     | 27260704      |
| ECLASS-7.0     | 27440402      |
| ECLASS-8.0     | 27440402      |
| ECLASS-9.0     | 27460201      |
| ECLASS-10.1    | 27440402      |
| ECLASS-11.1    | 27460201      |
| ECLASS-12.0    | 27460201      |
| ETIM-5.0       | EC002780      |
| GTIN           | 4048879038607 |
| HSコード          | 85366990      |
| Packaging unit | 1             |

| Installation                        |                   |
|-------------------------------------|-------------------|
| Connection cross-section solid max. | 4 mm <sup>2</sup> |

| Installation   Pin assignment |        |
|-------------------------------|--------|
| No. of poles                  | 24 + 7 |

| Device protection   Electrical    |   |
|-----------------------------------|---|
| Overvoltage category (EN 60664-1) | I |

| Device protection   Media |                 |
|---------------------------|-----------------|
| Flame resistance          | flame retardant |

| Mechanical data          |              |
|--------------------------|--------------|
| Type of socket connector | M (EN 60603) |

| Mechanical data   Material data |         |
|---------------------------------|---------|
| Material housing                | Plastic |

| Mechanical data   Mounting data |                           |
|---------------------------------|---------------------------|
| Mounting method                 | screwed, geschnappt       |
| Suitable for mounting type      | mounting rail, (EN 60715) |
| Height                          | 63 mm                     |
| Width                           | 137 mm                    |
| Depth                           | 170 mm                    |