





MSDD pass-through RJ45 CAT6A femal/femal, design silver

Pass-through

1 × RJ45, 8-pole metal, CAT6A (female/female)

Link to Product

Illustration

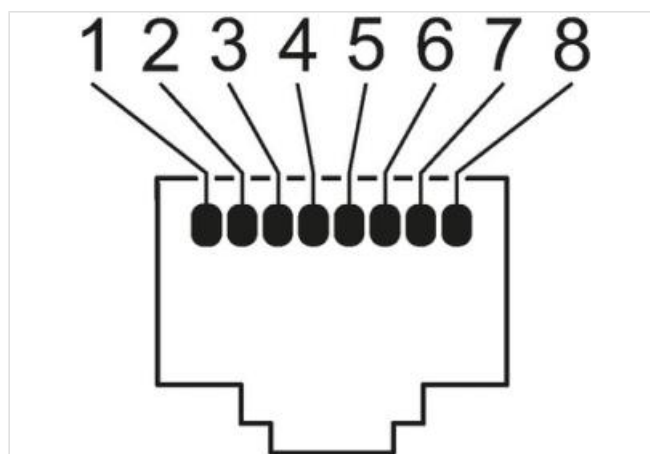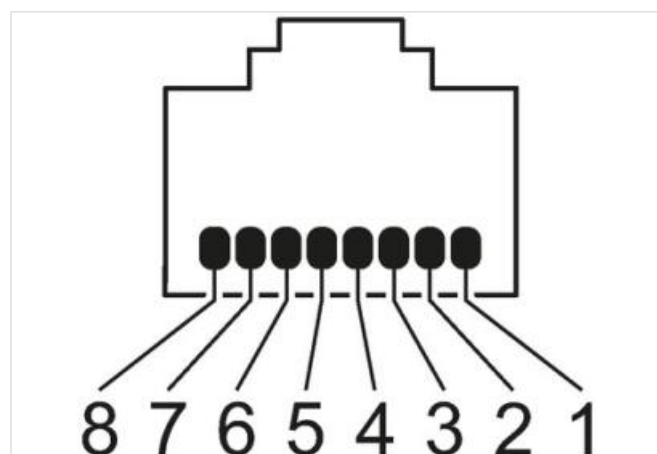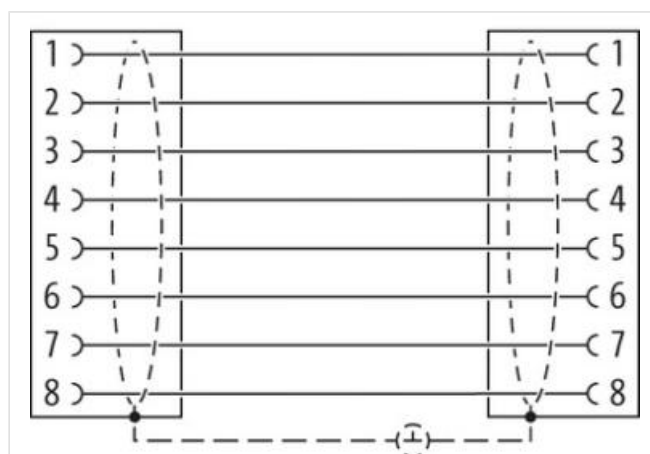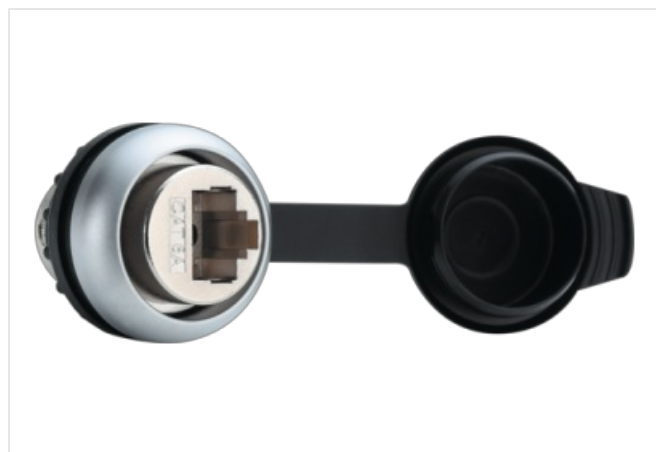

Product may differ from Image



取引条件	
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
GTIN	4065909037256
HSコード	85366990
Packaging unit	1
Electrical data Supply	
Operating voltage AC	24 V
Operating voltage DC	24 V
Operating current max.	1,5 A
Installation Connection	
Family construction form	RJ45
Gender	female
Gender Rear	female
Cable category min.	Cat6a
Device protection	
Shielded	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state
Device protection Mechanical	
Mechanical endurance	750 Cycles
Mechanical data Mounting data	
Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	20 mm
Approvals	
UL 50E	yes