






MSDD pass-through USB 3.0 form A, 0.6 m cable, design silver

Pass-through

1 × USB 3.0 (female/male/0.6 m cable) form A

Link to Product

Illustration

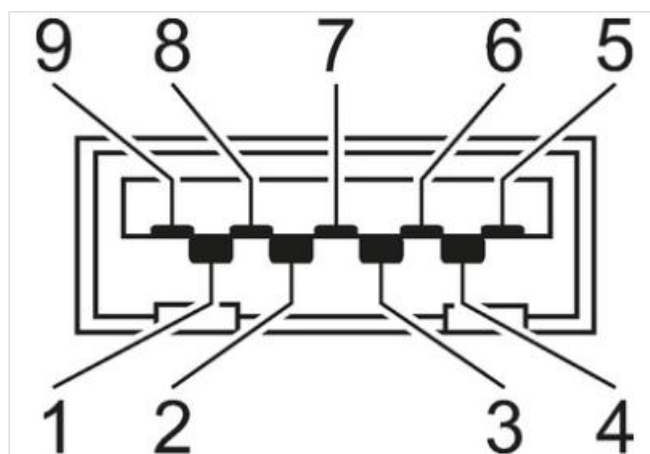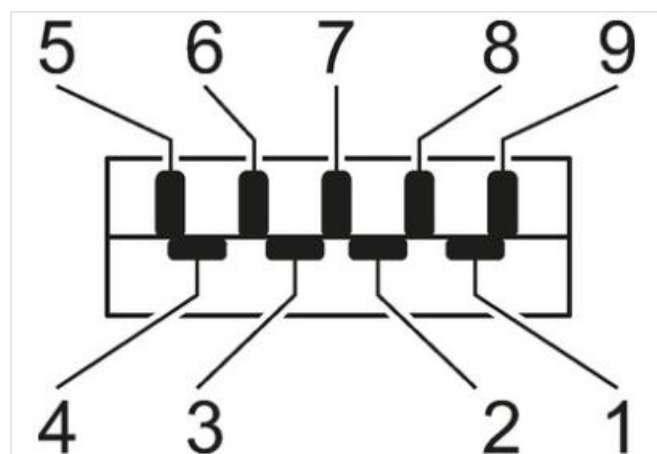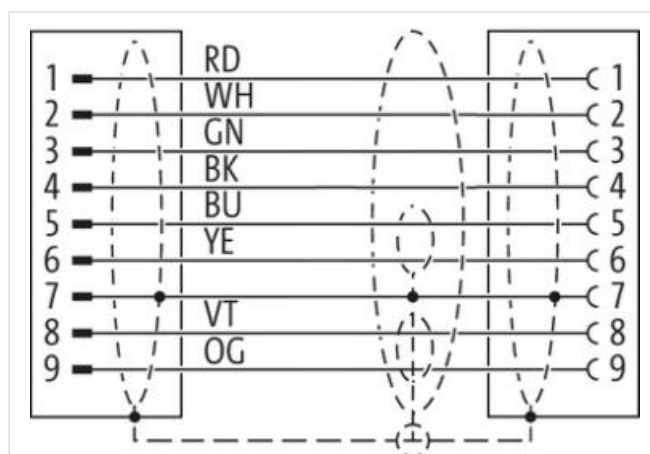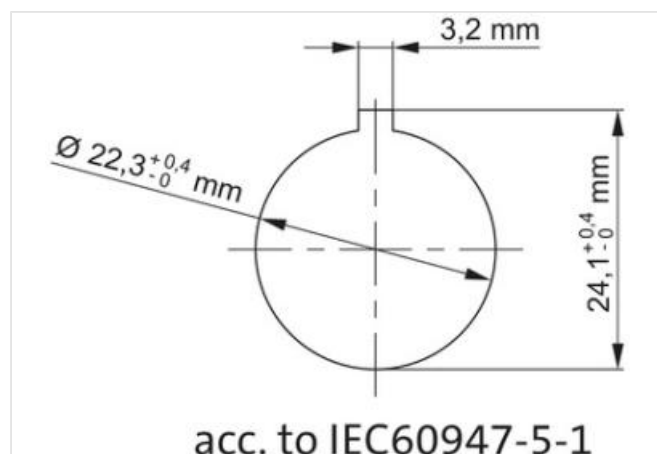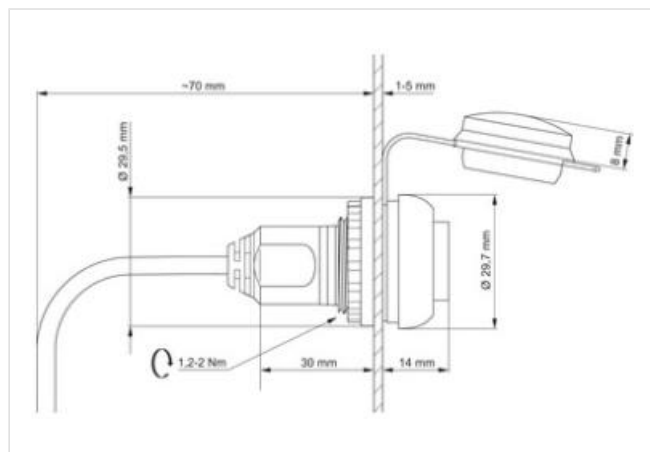

Product may differ from Image



取引条件	
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
GTIN	4048879432894
HSコード	85444290
Packaging unit	1
Electrical data Supply	
Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA
Industrial communication	
USB specification	3.0
Device protection	
Shielded	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state
Device protection Mechanical	
Mechanical endurance	1500 Cycles
Mechanical data Mounting data	
Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	30 mm
Approvals	
UL 50E	yes