

Signal tower Modlight70 Pro equipped with LED modules

blue,clear,M12 plug downward


Basic + LED modules + M12 (down)  
blue, clear

Link to Product

Illustration



Product may differ from Image

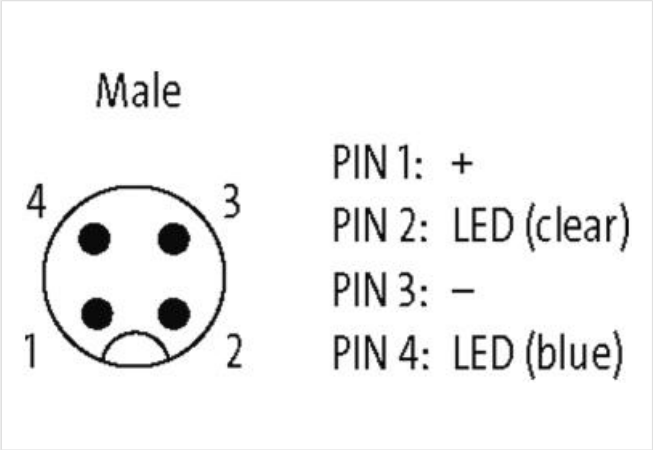

| 取引条件                                   |                  |
|----------------------------------------|------------------|
| ECLASS-6.0                             | 27371230         |
| ECLASS-6.1                             | 27371230         |
| ECLASS-7.0                             | 27371230         |
| ECLASS-8.0                             | 27371230         |
| ECLASS-9.0                             | 27371230         |
| ECLASS-10.1                            | 27371230         |
| ECLASS-11.1                            | 27371230         |
| ECLASS-12.0                            | 27371230         |
| ETIM-5.0                               | EC001042         |
| GTIN                                   | 4048879759960    |
| HSコード                                  | 85318070         |
| Packaging unit                         | 1                |
| Electrical data   Supply               |                  |
| Operating voltage DC                   | 24 V             |
| Operating voltage DC min.              | 21,6 V           |
| Operating voltage DC max.              | 26,4 V           |
| Current consumption max.               | 90 mA            |
| Device protection   Electrical         |                  |
| Degree of protection (EN IEC 60529)    | IP65             |
| Additional condition protection degree | inserted, locked |
| Mechanical data   Material data        |                  |
| Color housing                          | black            |

|                                          |                 |
|------------------------------------------|-----------------|
| Material housing                         | Plastic         |
| Mechanical data   Mounting data          |                 |
| Height                                   | 179 mm          |
| Width                                    | 70 mm           |
| Depth                                    | 70 mm           |
| Environmental characteristics   Climatic |                 |
| Operating temperature min.               | -20 °C          |
| Operating temperature max.               | 50 °C           |
| Connection type 2                        |                 |
| Family construction form                 | M12             |
| Gender                                   | male            |
| Coding                                   | A               |
| No. of poles                             | 4               |
| PIN 1                                    | 24 V DC (0 V)   |
| PIN 2                                    | LED-Modul CL    |
| PIN 3                                    | 0 V (24 V DC)   |
| PIN 4                                    | LED-Modul BU    |
| Mounting method                          | bayonet-locking |