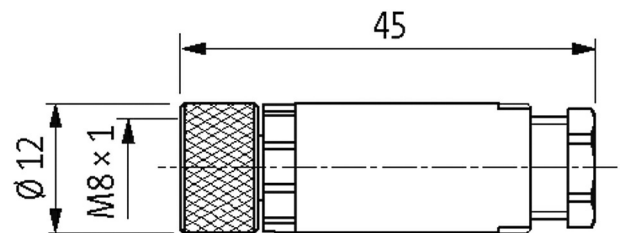
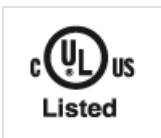


M8 FEMALE 0° FIELD-WIREABLE SCREW TERM.4-pol. 0,14...0.5mm²

メスストレート
M8 ,4極
ネジ端子
接続断面積： 0.14~0.5 mm²

[Link to Product](#)**Illustration**

Product may differ from Image

認証**Form**

Form 08631

Technical Data

Operating voltage	max. 60 V
Operating voltage (only UL listed)	30 V
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Material group	III
Connection cross section	0.14...0.5 mm ²
Sealing range (cable Ø)	3.5...5.0 mm
Protection	IP67 ネジ締込時 (EN 60529)
Over voltage category	III

General data

Pollution Degree	3
Temperature range	-40...+85 °C
Material (housing)	PA
Material (contact)	ブロンズ 金メッキ

Dimensions H×W×D 45×12×12 mm

取引条件

EAN 4048879224505

eClass 27279221



HSコード 85366990

Packaging unit 1

生産現国 DE

Sketch

Female

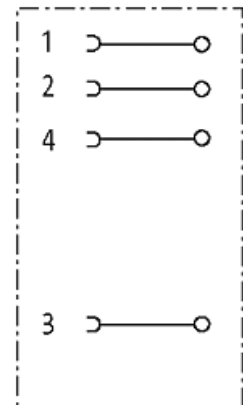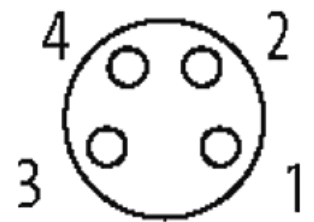

Product may differ from Image