

**M12 MALE 0° SHIELDED WIREABLE SCREW TERM.**5-pol. max.0,75mm<sup>2</sup> 4-6mm

オス ストレート

M12, 5極

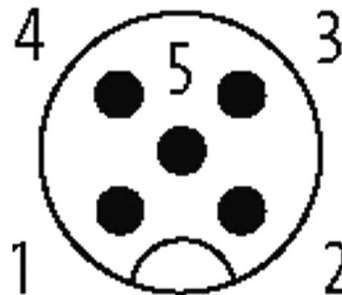
シールド

ネジ端子

締め付け範囲（ケーブル径）：4～6 mm

[Link to Product](#)**Illustration**

Male



Product may differ from Image

**Form**

Form 13301

**General data**

Temperature range -40...+85 °C

**Technical Data**

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Connection cross section max. 0.75 mm<sup>2</sup>

Sealing range (cable Ø) 4...6 mm

Protection IP67 ネジ締込時 (EN 60529)

Housing 真鍮, ニッケルメッキ

**取引条件**

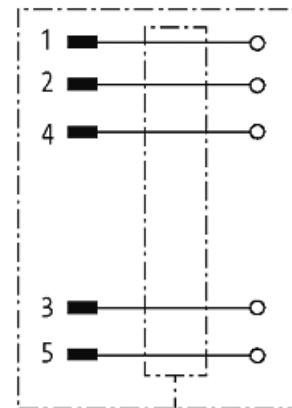
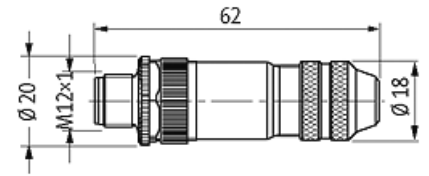
EAN 4048879198844

eClass 27279221

HSコード 85366990

Packaging unit 1

生産現国 DE

**Sketch**

Product may differ from Image