



Adaptor M12 female 0° X-cod. / RJ45 90°

8-pol., shielded, CAT6A


Adapter
M12 – RJ45, top connection
Female straight – female 90°
8-pole
X-coded
Gigabit
Ethernet CAT6A
shielded
Cap nut

Link to Product

Illustration

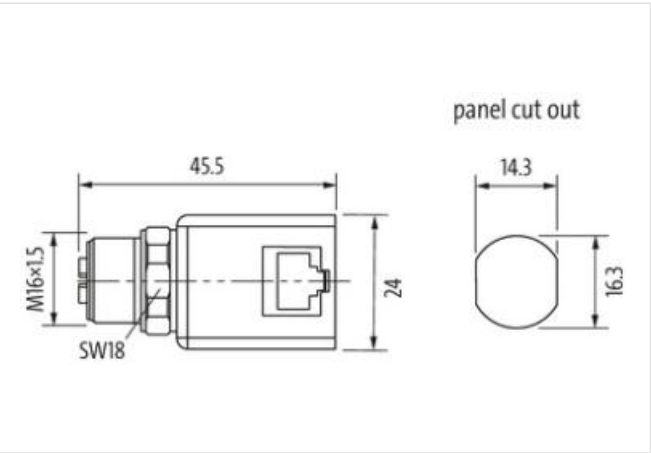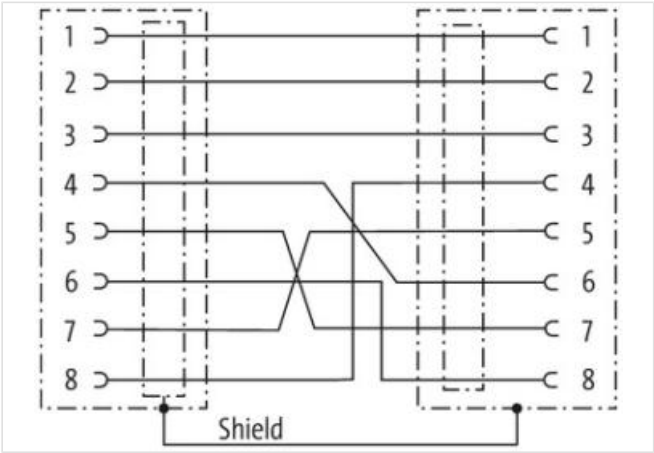

Product may differ from Image

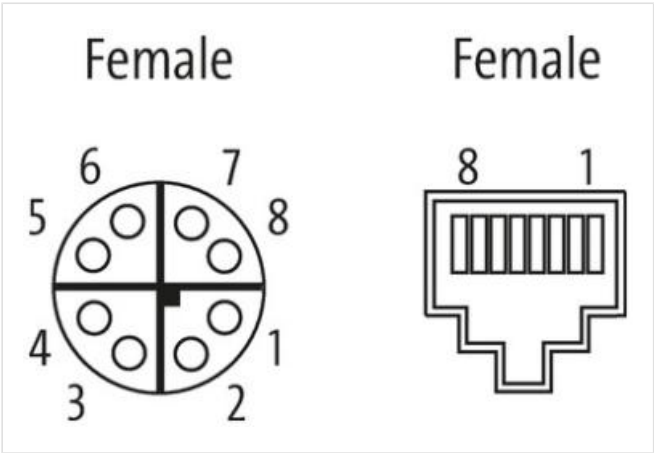

Side 1	
Family construction form	M12
Coding	X
取引条件	
ECLASS-6.0	27143423
ECLASS-6.1	27279221
ECLASS-7.0	27440104

ECLASS-8.0	27440104
ECLASS-9.0	27440106
ECLASS-10.1	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
ETIM-5.0	EC002640
GTIN	4048879699419
HSコード	85366990
Packaging unit	1

Electrical data | Supply

Operating current max. 1,75 A

Industrial communication

Supported protocol	Ethernet
Transfer parameters	CAT6A

Installation | Connection

Width across flats SW18

Important installation notes

Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.
Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.