

**M8 male 0° / M8 female 90° A-cod. snap-in**

PVC 3x0.25 bk UL/CSA 2m


Male straight – female 90°

M8 (Snap In) – M8 (Snap In), 3-pole


Further cable lengths on request.



Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

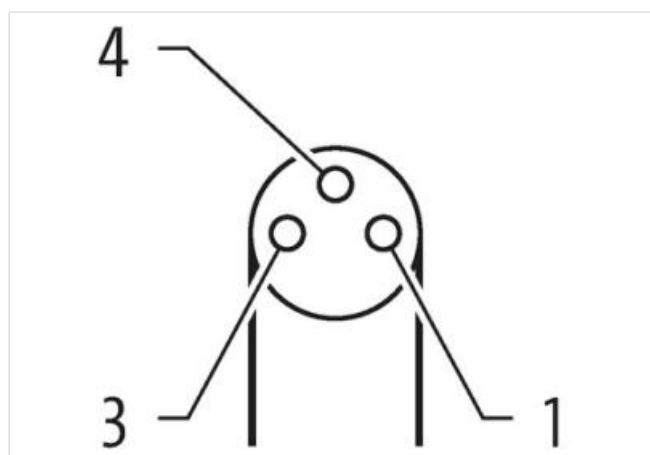[Link to Product](#)**Illustration**

|   |    |   |
|---|----|---|
| 1 | BN | 1 |
| 3 | BU | 3 |
| 4 | BK | 4 |

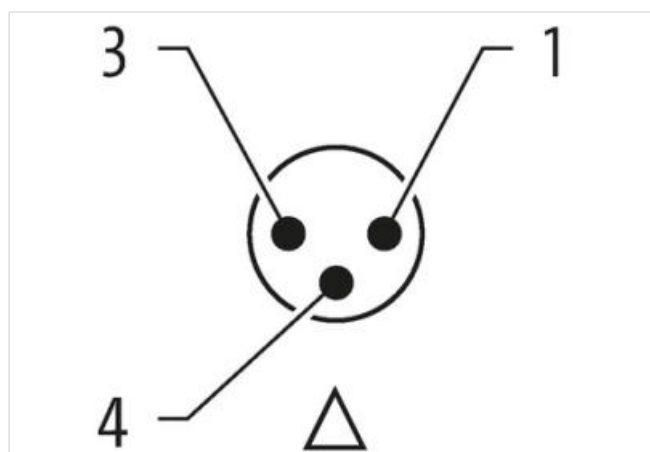

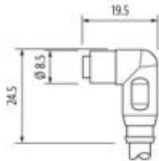 

Product may differ from Image



|                                           |                  |
|-------------------------------------------|------------------|
| Cable length                              | 2 m              |
| Side 1                                    |                  |
| Thread                                    | M8               |
| suitable for corrugated tube (internal Ø) | 6,5 mm           |
| 取引条件                                      |                  |
| ECLASS-6.0                                | 27279218         |
| ECLASS-6.1                                | 27279218         |
| ECLASS-7.0                                | 27279218         |
| ECLASS-8.0                                | 27279218         |
| ECLASS-9.0                                | 27060311         |
| ECLASS-10.1                               | 27060311         |
| ECLASS-11.1                               | 27060311         |
| ECLASS-12.0                               | 27060311         |
| ETIM-5.0                                  | EC001855         |
| GTIN                                      | 4048879666466    |
| HSコード                                     | 85444290         |
| Packaging unit                            | 1                |
| Electrical data   Supply                  |                  |
| Operating voltage AC max.                 | 50 V             |
| Operating voltage DC max.                 | 60 V             |
| Operating voltage AC (UL-listed)          | 30 V             |
| Operating voltage DC (UL-listed)          | 30 V             |
| Current operating per contact max.        | 4 A              |
| Device protection   Electrical            |                  |
| Degree of protection (EN IEC 60529)       | IP65             |
| Additional condition protection degree    | inserted, locked |
| Pollution Degree                          | 3                |
| Rated surge voltage                       | 1,5 kV           |
| Material group (IEC 60664-1)              | I                |
| Mechanical data   Material data           |                  |
| Material housing                          | PUR              |



|                          |                                                      |
|--------------------------|------------------------------------------------------|
| Oil resistance           | Good, application-related testing   DIN EN 60811-404 |
| Bending radius (fixed)   | 5 x Outer diameter                                   |
| Bending radius (dynamic) | 10 x Outer diameter                                  |