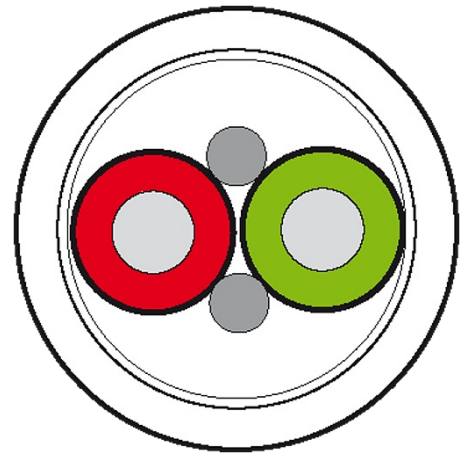


cable drum Ø 355mm

PUR 1x2x0,64 shielded vt UL/CSA+dragchain 100m

ケーブルドラム (100 m)
 PROFIBUS
 1 × 2 × 0.64 mm²
 PUR (UL/CSA)
 C-トラック用
 10 Mio.

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

| | |
|----------------------------|------------------------------------|
| No./diameter of wires | 1 × 2 × 0.25 mm ² |
| Wire isolation | PE (赤, 緑) |
| C-track properties | 10 Mio. |
| Jacket Color | 紫 |
| Material (jacket) | PUR (UL/CSA) |
| Outer Ø | 7.8 mm ±5% |
| Bend radius (moving) | 12× 外径 |
| Temperature range (fixed) | -40...+80 °C |
| Temperature range (mobile) | -20...+60 °C |
| Cable identification | 840 |
| Approval (cable) | UL (AWM-Style 20236/1589), CSA; CE |
| Cable weight [g/m] | 82,50 |
| Material (wire) | 裸銅線 |
| Resistor (core) | max. 78 Ω/km (20 °C) |
| Single wire Ø (core) | 0.127 mm |
| Construction (core) | 19 × 0.127 mm |
| Diameter (core) | 1 × 2 × 0.25 mm ² |
| AWG | AWG 24 に類似 |
| Material (wire isolation) | PE |
| Wire-Ø incl. isolation | 2.55 mm ±5% |
| Color/numbering of wires | 赤、緑 |
| Stranding combination | 2心線のより線 |
| Shield | yes |
| optical shield cover | min. 70% |

| | |
|---------------------------------|-------------------------|
| Material (jacket) | PUR |
| Outer-Ø (jacket) | 7.8 mm ±5% |
| Color (jacket) | 紫 |
| chemical resistance | 優れた耐油性、耐ガソリン性および耐化学薬品性 |
| thermal resistance | 難燃剤 |
| Nominal voltage | 250 V |
| Temperature range (fixed) | -40...+80 °C |
| Temperature range (mobile) | -20...+60 °C |
| Bend radius (fixed) | 10× 外径 |
| Bend radius (moving) | 12× 外径 |
| No. of bending cycles (C-track) | max. 10 Mio. (25 °C) |
| Traversing distance (C-track) | max. 5 m (horizontal) |
| Travel speed (C-track) | max. 3 m/s |
| Acceleration (C-track) | max. 5 m/s ² |

取引条件

| | |
|----------------|---------------|
| EAN | 4048879328838 |
| eClass | 27062011 |
| HSコード | 85444993 |
| Packaging unit | 1 |
| 生産現国 | IT |