

**M12 FEMALE 0° V2A**

PVC 4X0.34 black UL/CSA 5m

M12, 4



7005 - M12 Lite -

1.4305 V2A


[Link to Product](#)

Illustration

stay connected

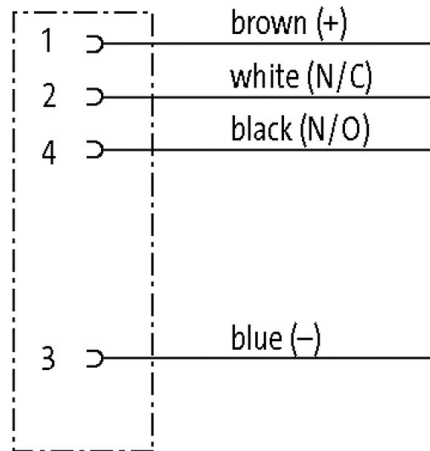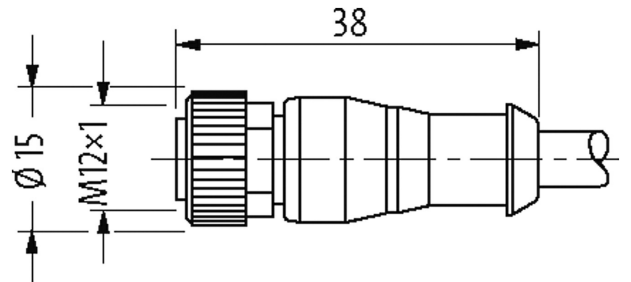

Female

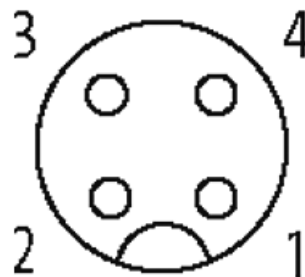

Product may differ from Image



\* UL/CSA

**Form**

Form 12221

/ 4 x 0.34 mm<sup>2</sup>

PVC ( , , )

	PVC (UL/CSA)
	5.0 mm ±5%
	10×
	-30...+80 °C
	-5...+80 °C
	614
	1 (PVC)
( )	UL (AWM-Style 2464/1731), CSA
[g/m]	40,70
( )	max. 60 Ω/km (20 °C)
( )	0.15 mm
( )	19× 0.15 mm ( 5)
	4× 0.34 mm <sup>2</sup>
AWG	AWG 22
	PVC
	CFC
	45 ±5 D
	1.25 mm ±5%
/	
	4
	no
	PVC
)	CFC
Shore hardness (jacket)	85 ±5 A
( )	5.0 mm ±5%
( )	
	UL 300 V AC
	2000 V AC
	DIN VDE 0298-4
	-30...+80 °C
	-5...+80 °C
	5×
	10×
	max. 250 V AC/DC
UL listed	max. 30 V AC/DC
	max. 4 A
	IEC 60664-1, category I
	(M12×1 mm) 0.6 Nm
	M12 (SW13)
	IP66K, IP67 EN 60529
	1.4305 V2A
	PUR
( )	10 mm
	DIN EN 61076-2-101 (M12)
	3

-25 +85 ,

EAN	4048879295512
eClass	27279218
HS	85444290
Packaging unit	1
	DE