

RJ45 module - male, adapter


Male
RJ45
Adapter for industry plug conectors
Technical data will be only guaranteed with Murrelektronik components.
The clip 70MH-ZZ100-0000000 is needed (2×)

Link to Product

Illustration



Product may differ from Image

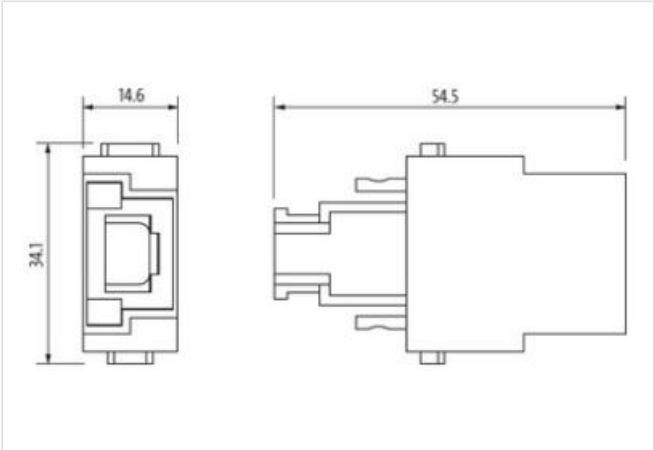

取引条件	
ECLASS-6.0	27143424
ECLASS-6.1	27261204
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440204
ECLASS-10.1	27440204
ECLASS-11.1	27440204
ECLASS-12.0	27440204
ETIM-5.0	EC000437
GTIN	4048879664080
HSコード	85389099
Packaging unit	1
Electrical data Supply	
Operating voltage AC	50 V
Operating voltage DC	50 V
Industrial communication	
Transfer parameters	CAT5e
Installation Connection	
Gender	male
Mating cycles min.	500
Device protection Electrical	

Pollution Degree	3
Rated surge voltage	0,8 kV
Overvoltage category (EN 60950-1)	III
Mechanical data Material data	
Combustibility class (UL94)	V-0
Material housing	PC
Mechanical data Mounting data	
Number of module slots	1
Height	41 mm
Width	34,1 mm
Depth	14,6 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	70 °C