

Pneumatic module - female & male, 3-pole


Pneumatic
Male/female
3-pole
Internal hose Ø 1.6, 3, 4 mm
Technical data will be only guaranteed with Murrelektronik components.
The clip 70MH-ZZ100-0000000 is needed (2×)

Link to Product

Illustration



Product may differ from Image

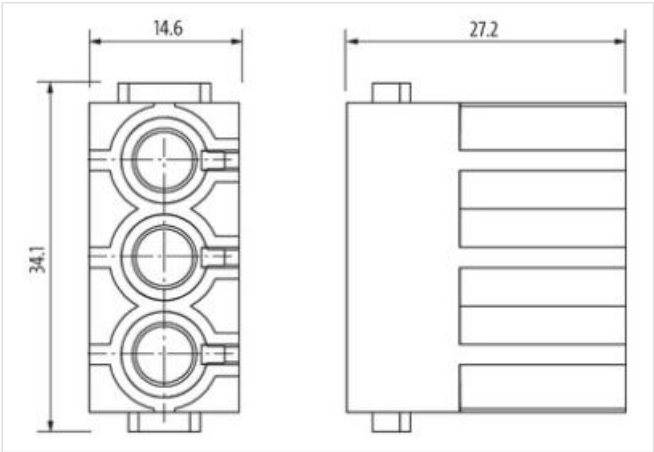

取引条件	
ECLASS-6.0	27440209
ECLASS-6.1	27261204
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440204
ECLASS-10.1	27440204
ECLASS-11.1	27440204
ECLASS-12.0	27440204
ETIM-5.0	EC000438
GTIN	4048879664141
HSコード	85389099
Packaging unit	5
Installation Connection	
Gender	male/female
Mating cycles min.	500
Installation Pin assignment	
No. of poles	3
Device protection Electrical	
Pollution Degree	3
Mechanical data Material data	

Combustibility class (UL94)	V-0
Material housing	PC
Mechanical data Mounting data	
Number of module slots	1
Height	27,2 mm
Width	34,1 mm
Depth	14,6 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	80 °C